

# E10996




## Patchcords with valve plug

VVDAB031--S00,6H03STGH030MSS

Article no longer available - archive entry

Alternative articles: E11422

When selecting an alternative article and accessories please note that technical data may differ!

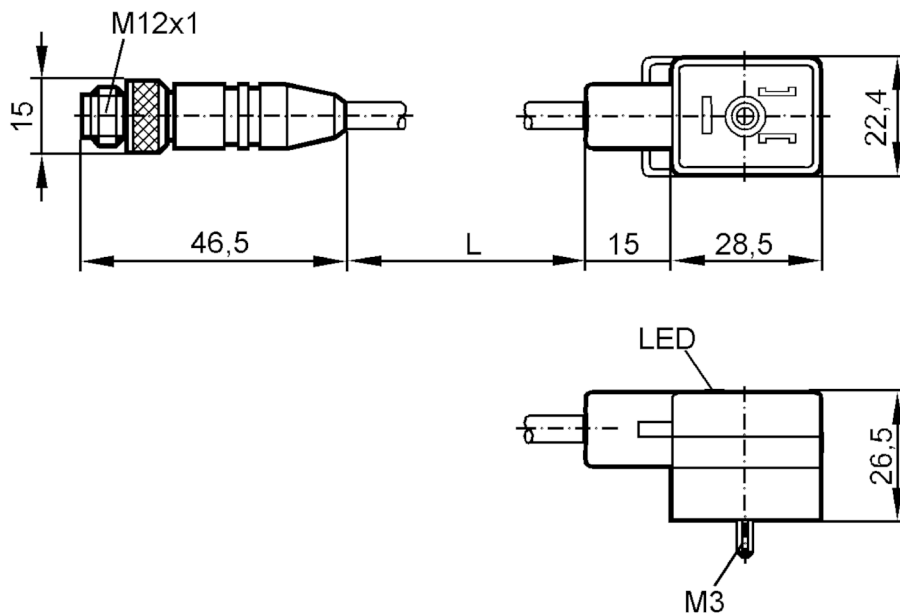

| Application                   |                  |                      |
|-------------------------------|------------------|----------------------|
| System                        |                  | Halogen-free         |
| Electrical data               |                  |                      |
| Operating voltage             | [V]              | < 24 AC/DC           |
| Overvoltage protection        |                  | yes; (VDR)           |
| Operating conditions          |                  |                      |
| Ambient temperature           | [°C]             | -25...90             |
| Protection                    |                  | IP 67                |
| Mechanical data               |                  |                      |
| Dimensions                    | [mm]             | 15 x 15 x 46.5       |
| Material                      |                  | TPU (urethane)       |
| Molded-body material          |                  | TPU (urethane)       |
| Material nut                  |                  | brass, nickel-plated |
| Displays / operating elements |                  |                      |
| Display                       | Switching status | 1 x LED, yellow      |
| Accessories                   |                  |                      |
| Items supplied                |                  | screw                |
|                               |                  | panel for labelling  |
| Remarks                       |                  |                      |
| Pack quantity                 |                  | 1 pcs.               |

# E10996




## Patchcords with valve plug

VVDAB031--S00,6H03STGH030MSS

### Electrical connection - plug

 
Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



### Electrical connection

Cable: 0.6 m, PUR, Halogen-free; 3 x 0.5 mm<sup>2</sup>

### Connection

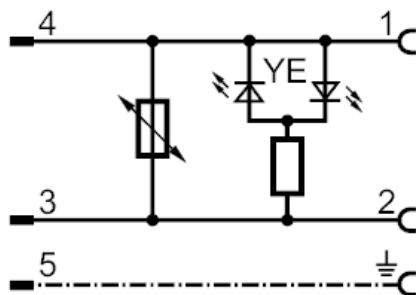

### Electrical connection - Socket

Connector: 1 x valve type B DIN, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

