


E10999



Patchcords with valve plug

VVDAB031--S0005H03STGH030MSS

Article no longer available - archive entry

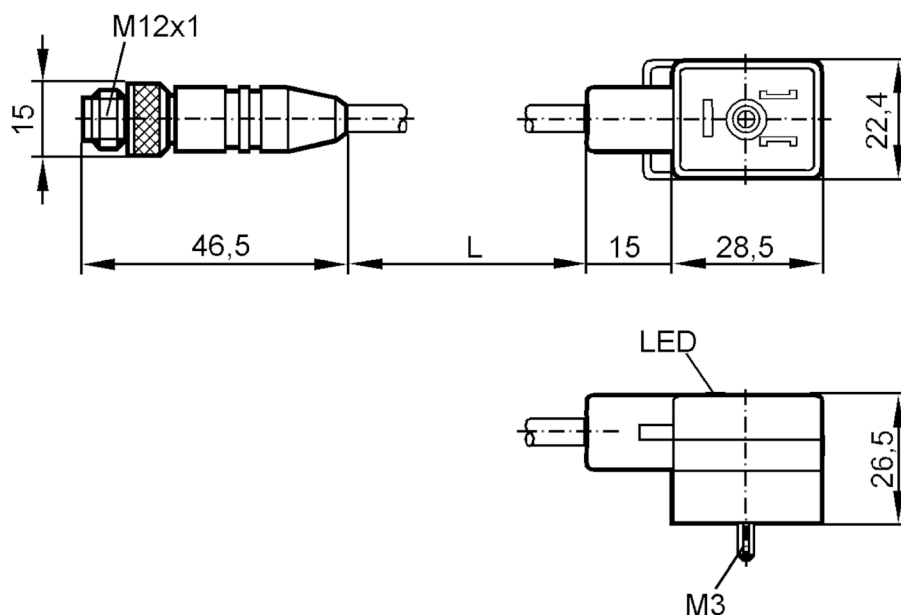

Application

System Halogen-free

Electrical data

Operating voltage [V] < 24 AC/DC

Overvoltage protection yes; (VDR)

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 15 x 15 x 46.5

Material TPU (urethane)

Molded-body material TPU (urethane)

Material nut brass, nickel-plated

Displays / operating elements

Display Switching status 1 x LED, yellow

Accessories

Items supplied screw
panel for labelling

Remarks

Pack quantity 1 pcs.

E10999




Patchcords with valve plug

VVDAB031--S0005H03STGH030MSS

Electrical connection - plug

 
Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Electrical connection

Cable: 5 m, PUR, Halogen-free; 3 x 0.5 mm²

Connection

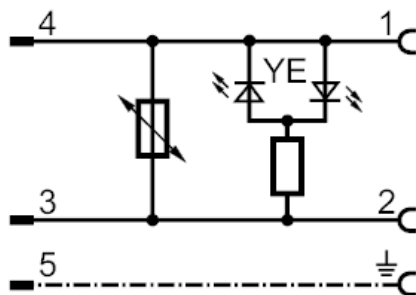

Electrical connection - Socket

Connector: 1 x valve type B DIN, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

