


E10059



Female wirable connectors

SDOAC030--SFKPG

Article no longer available - archive entry

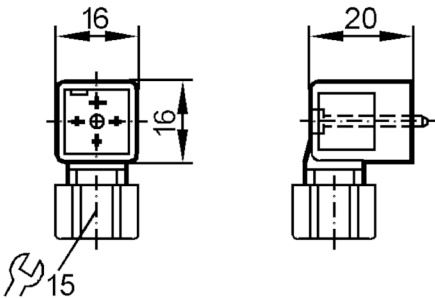

Electrical data

Operating voltage	[V]	< 250 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 65

Mechanical data

Material		PA
Molded-body material		PA

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø ...6.5 mm

Electrical connection - Socket

Connector: 1 x valve type C DIN, angled; Moulded body: PA



E10059



Female wirable connectors

SDOAC030--SFKPG

Connection

