

E10064




Female wirable connectors

SDOAH042PLSFKPG

Article no longer available - archive entry

Alternative articles: E11510
When selecting an alternative article and accessories please note that technical data may differ!

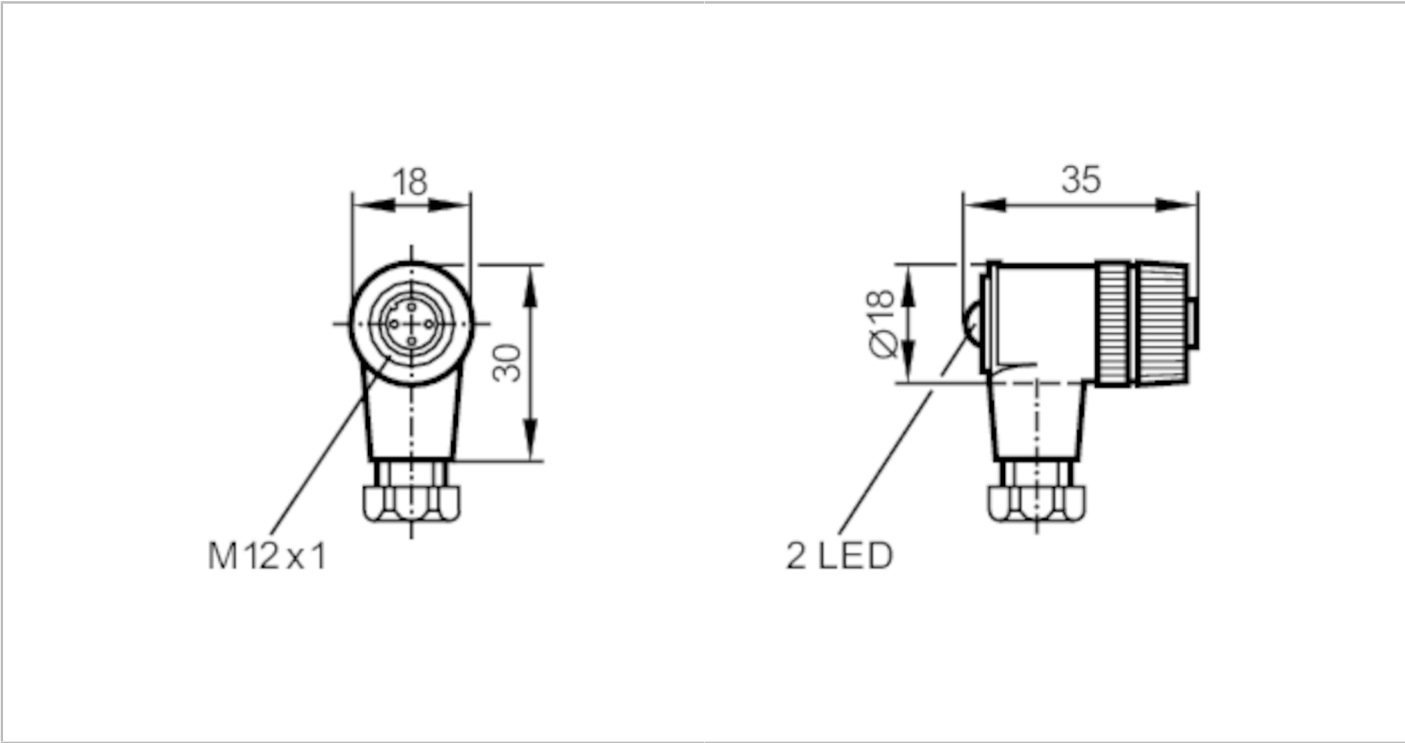

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Dimensions	[mm]	30 x 18 x 35
Material		PBT; PA
Molded-body material		PBT / PA
Material nut		PA
Displays / operating elements		
Display	Switching status	1 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10064



Female wirable connectors

SDOAH042PLSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PBT / PA; Locking: PA



Connection

