


E10085



Female wirable connectors

SDOAT052--SFKPG

Article no longer available - archive entry

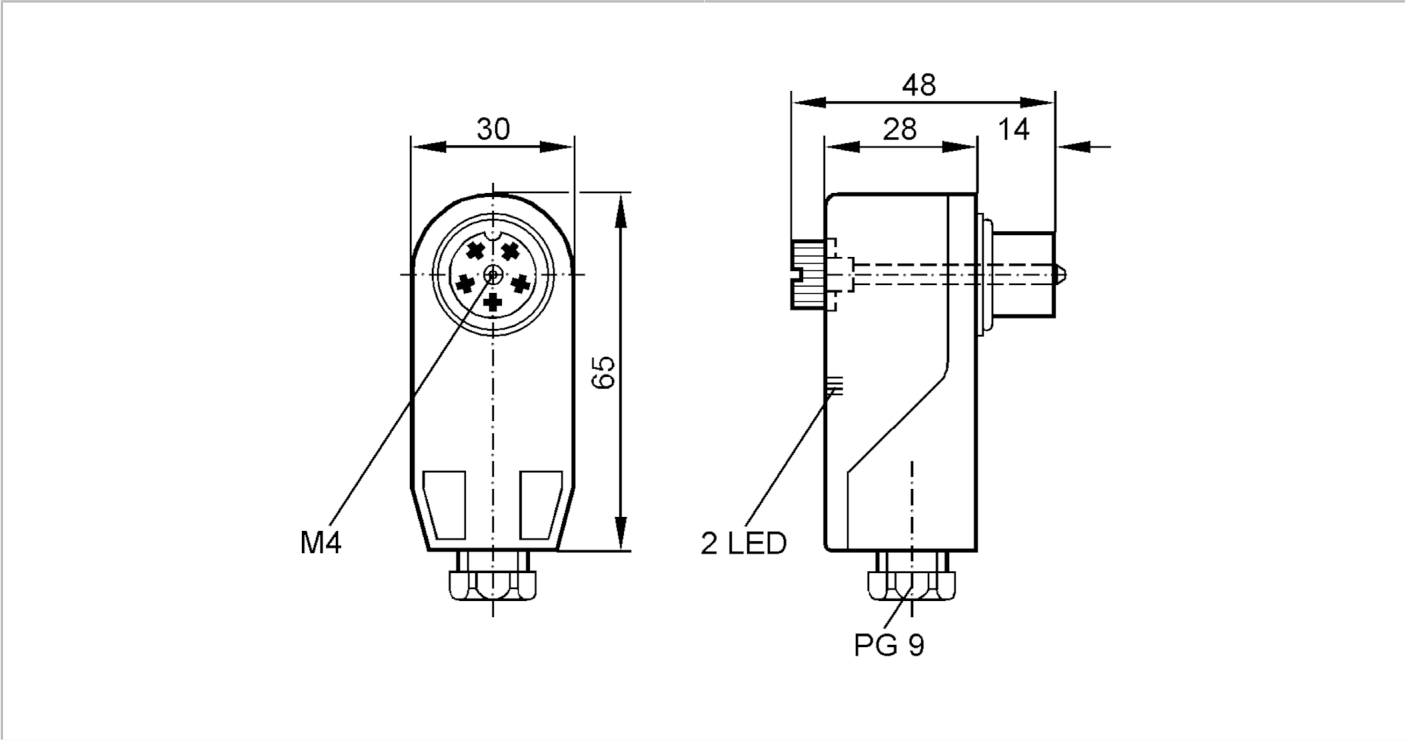

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		NPN
Operating conditions		
Ambient temperature	[°C]	-30...80
Protection		IP 65
Mechanical data		
Dimensions	[mm]	48 x 30 x 65
Material		PA
Molded-body material		PA
Material nut		PA
Displays / operating elements		
Display	Switching status	1 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10085



Female wirable connectors

SDOAT052--SFKPG

Electrical connection

terminals: ...1.5 mm²; Cable gland: PG 9

Electrical connection - Socket

Connector: 1 x Ø 28 mm, angled; coding: A; Moulded body: PA; Locking: PA



Connection

