


E10087



Female wirable connectors

SDOAT050--SFKPG

Article no longer available - archive entry

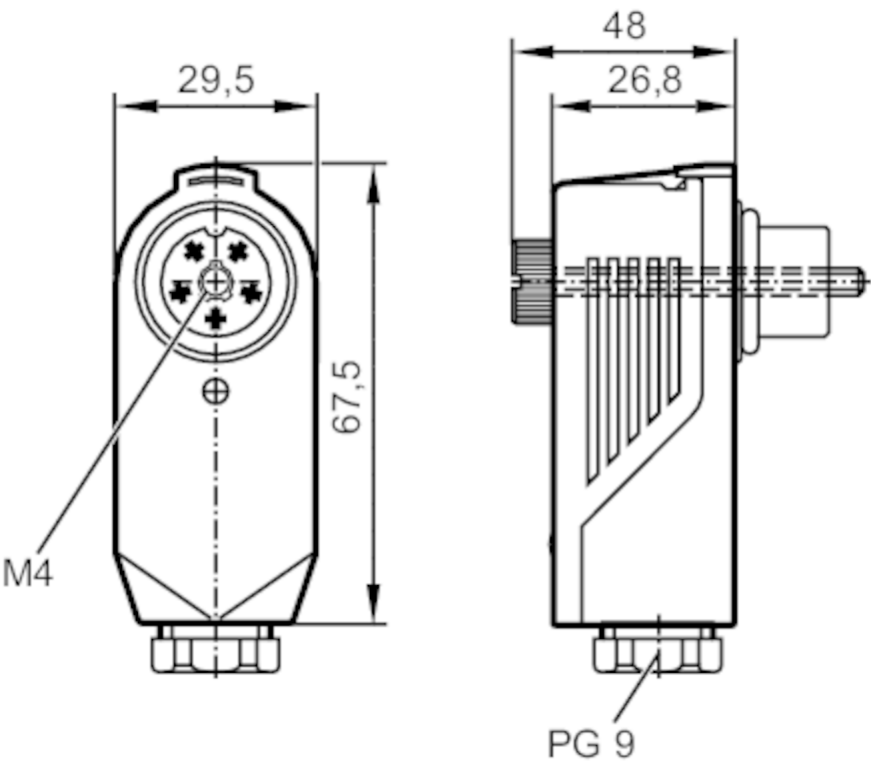

Electrical data		
Operating voltage	[V]	20...250 AC/DC
Operating conditions		
Ambient temperature	[°C]	-25...80
Protection		IP 65
Mechanical data		
Weight	[g]	65.2
Material		PA
Molded-body material		PA
Remarks		
Pack quantity		1 pcs.

E10087



Female wirable connectors

SDOAT050--SFKPG

Electrical connection

terminals: ...1.5 mm²; Cable sheath: Ø 5...11 mm

Electrical connection - Socket

Connector: 1 x Ø 28 mm, angled; coding: A; Moulded body: PA



Connection

