

# E10088




## Female wirable connectors

SDOAH042PLSFKPG

Article no longer available - archive entry

Alternative articles: E11510  
When selecting an alternative article and accessories please note that technical data may differ!

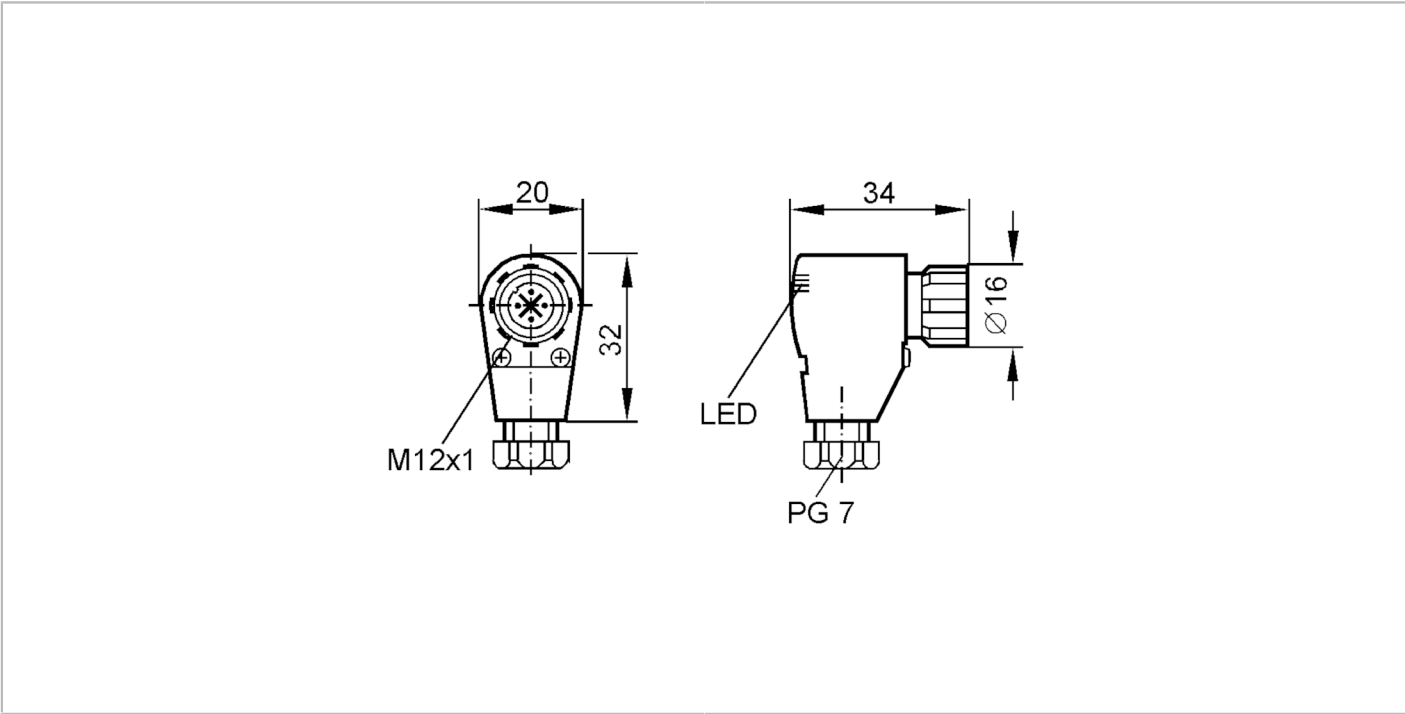

| Electrical data               |                  |                 |
|-------------------------------|------------------|-----------------|
| Operating voltage             | [V]              | 10...30 DC      |
| Outputs                       |                  |                 |
| Electrical design             |                  | PNP             |
| Operating conditions          |                  |                 |
| Ambient temperature           | [°C]             | -30...80        |
| Protection                    |                  | IP 65           |
| Mechanical data               |                  |                 |
| Dimensions                    | [mm]             | 20 x 34 x 32    |
| Material                      |                  | PA              |
| Molded-body material          |                  | PA              |
| Material nut                  |                  | PA              |
| Displays / operating elements |                  |                 |
| Display                       | Switching status | 1 x LED, yellow |
|                               | Power            | 1 x LED, green  |
| Remarks                       |                  |                 |
| Pack quantity                 |                  | 1 pcs.          |

# E10088



## Female wirable connectors

 
SDOAH042PLSFKPG

### Electrical connection

terminals: ...0.5 mm<sup>2</sup>; Cable gland: PG 7

### Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: PA



### Connection

