

E10094




Female wirable connectors

SDOAH042ZDSFKPG

Article no longer available - archive entry

Alternative articles: E11510
When selecting an alternative article and accessories please note that technical data may differ!

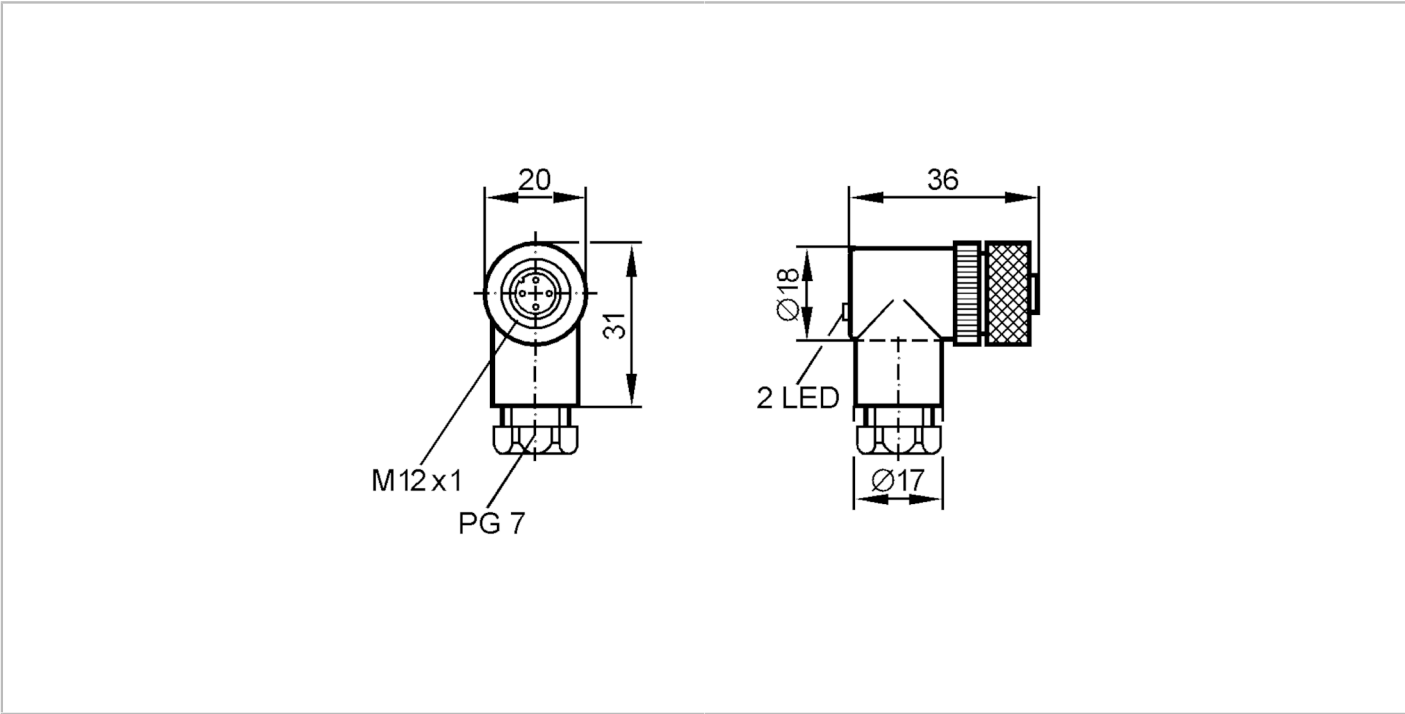

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	36 x 20 x 31
Material		PA
Molded-body material		PA
Material nut		diecast zinc, nickel-plated
Displays / operating elements		
Display	Switching status	1 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10094



Female wirable connectors

SDOAH042ZDSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable gland: PG 7

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: diecast zinc, nickel-plated



Connection

