


E10105



Female cordset

ADOGB030PLS0005E03


Article no longer available - archive entry

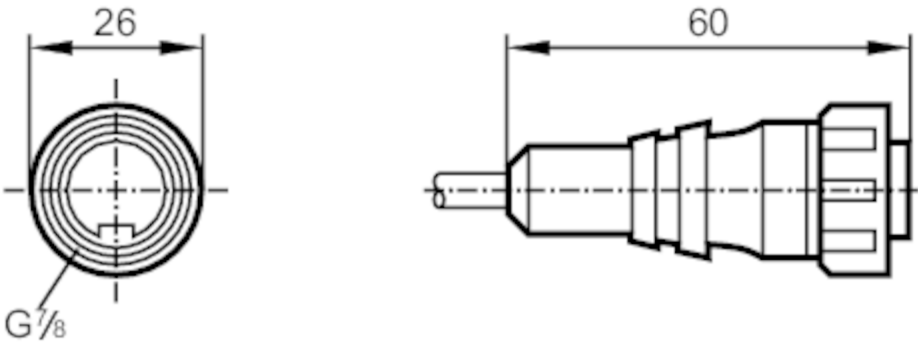

Electrical data		
Operating voltage	[V]	10...30 DC
Operating conditions		
Ambient temperature	[°C]	-40...90
Protection		IP 68
Mechanical data		
Dimensions	[mm]	26 x 26 x 60
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		PA
Remarks		
Pack quantity		1 pcs.

Electrical connection	
Cable: 5 m, PVC, orange, Ø 5 mm; 3 x 0.75 mm² (22 x Ø 0.2 mm)	

Electrical connection - Socket	
Connector: 1 x 7/8", straight; coding: A; Moulded body: TPU (urethane); Locking: PA	

 


E10105



Female cordset

ADOGB030PLS0005E03

Connection

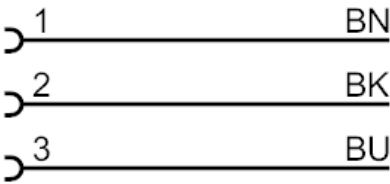

BK =	Core colors :	black
BN =		brown
BU =		blue