


E10137



Female wirable connectors


SDOGJ040PLSFKPG

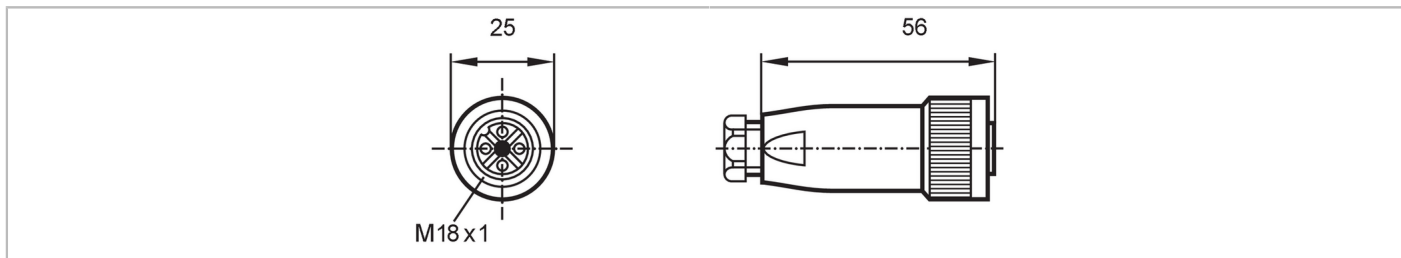

Electrical data	
Operating voltage [V]	< 250 AC/DC
Max. current load total [A]	4; (...40 °C)
Operating conditions	
Ambient temperature [°C]	-40...85
Protection	IP 65
Mechanical data	
Weight [g]	26.6
Dimensions [mm]	25 x 25 x 56
Molded-body material	PA
Material nut	ULTRAMID
Remarks	
Pack quantity	1 pcs.

Electrical connection
terminals: ...0.75 mm²; Cable sheath: Ø 6...8 mm

Electrical connection - Socket
Connector: 1 x M18, straight; coding: A; Contacts: 4; Moulded body: PA; Locking: ULTRAMID



Connection

