


E10150



Female cordset

ADOAH042ZDS0002A03

Article no longer available - archive entry

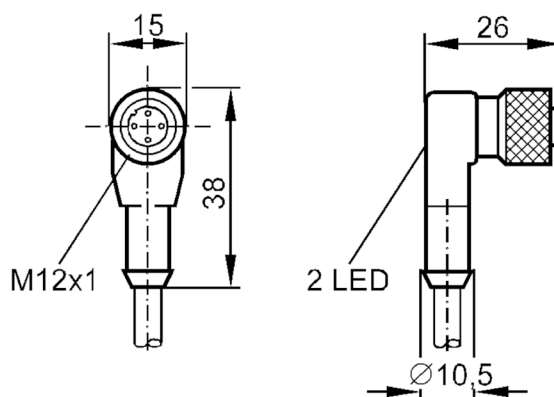

Electrical data

Operating voltage [V] 10...30 DC

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -30...90

Protection IP 67

Mechanical data

Dimensions [mm] 26 x 15 x 38

Material PUR

Molded-body material PUR

Material nut brass, nickel-plated

Displays / operating elements

Display	Switching status	1 x LED, yellow
	Power	1 x LED, green

Remarks

Pack quantity 1 pcs.

E10150



Female cordset

ADOAH042ZDS0002A03

Electrical connection


Cable: 2 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.34 mm²

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



Connection

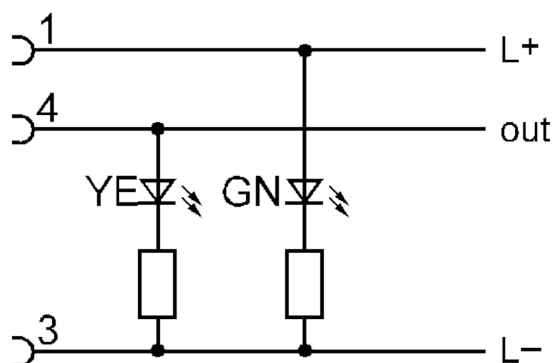

BK =
BN =
BU =

Core colors :
black
brown
blue