


E10155



Limit plunger

LIMIT PLUNGERS ITB

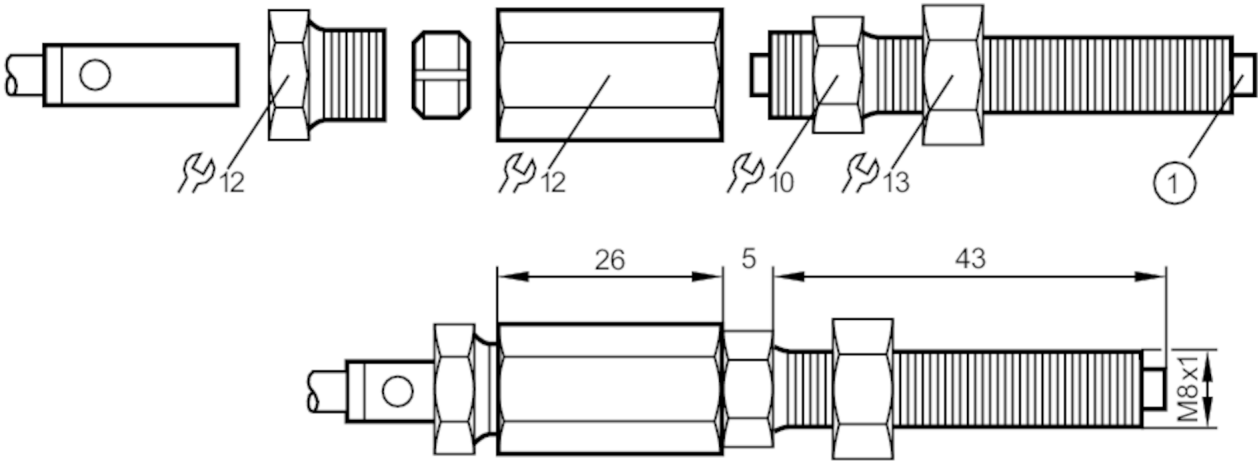

1 movable bolt with spring return stroke 1.5mm, Ø 5.5mm

Application

Design

for type, Ø 6,5 mm, Sn = 1mm b

Mechanical data

Weight

[g]

44.4

Material

Limit plunger: free cutting steel; plunger: steel (1.0503 / C45K) hardened on front; knurled nut: brass nickel-plated

Activation force

[N]

4.9...7845

Remarks

Pack quantity

1 pcs.