

E10188




Female cordset

ADOAH040MSS0002A02

Article no longer available - archive entry

Alternative articles: EVC164
When selecting an alternative article and accessories please note that technical data may differ!

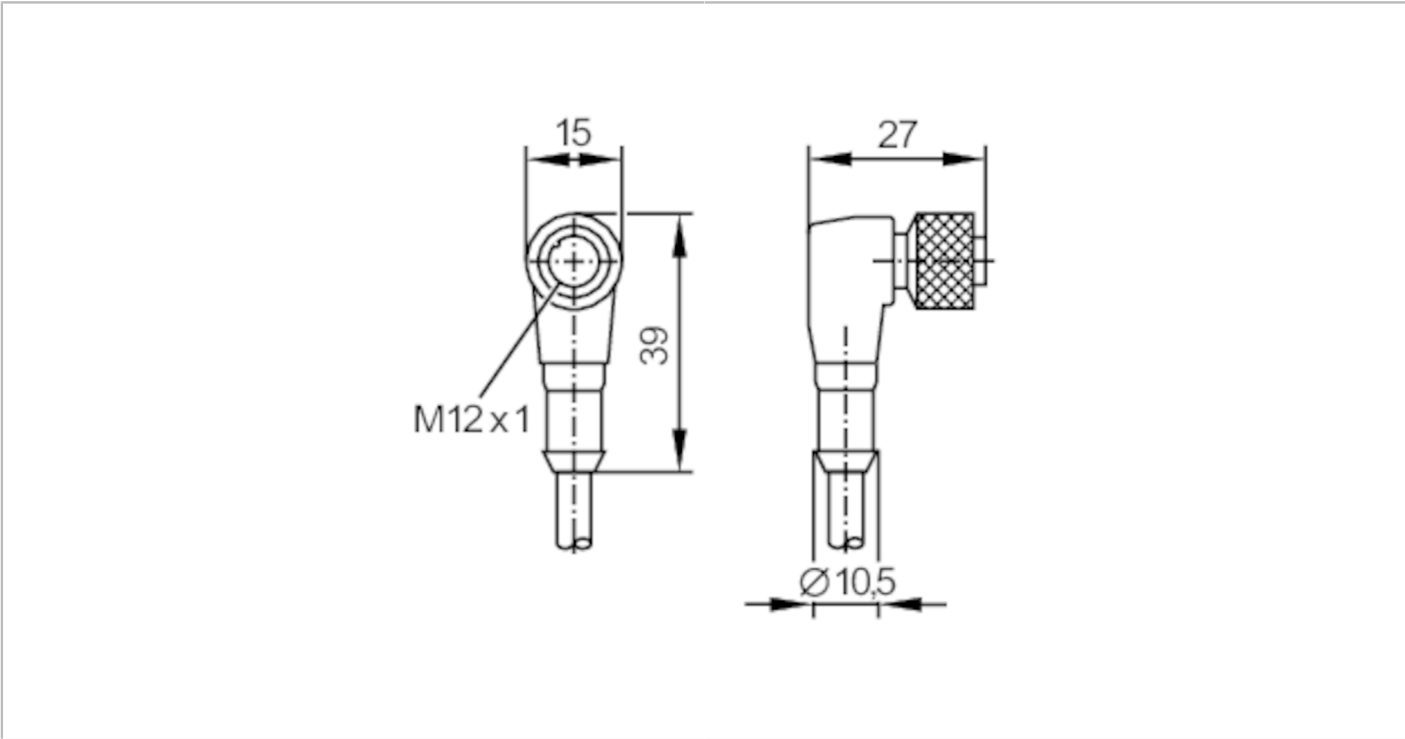

Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10188



Female cordset


ADOAH040MSS0002A02

Electrical connection


Cable: 2 m, PUR / PVC, orange, Ø 5 mm; 2 x 0.34 mm² (180 x Ø 0.05 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

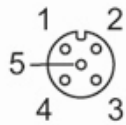

Connection

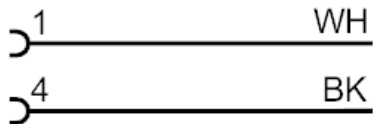

BK = Core colors :
WH = black
white