


E10207



Female cordset

ADOGG030--S0002E03

Article no longer available - archive entry

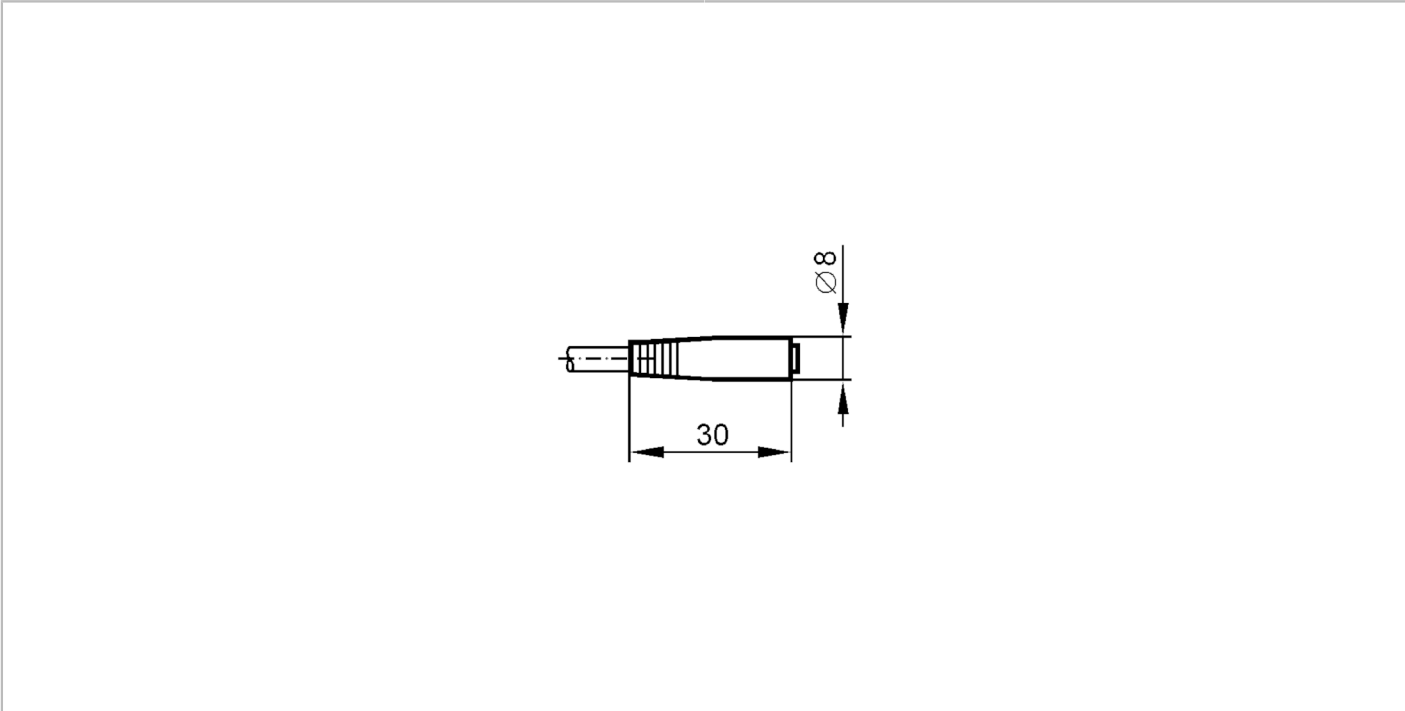

Electrical data		
Operating voltage	[V]	< 60 AC/DC
Protection class		III


Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data		
Dimensions	[mm]	8 x 8 x 30
Material		PUR
Molded-body material		PUR

Remarks		
Pack quantity		1 pcs.

Electrical connection		
Cable: 2 m, PVC, black, Ø 4.2 mm; 3 x 0.25 mm² (128 x Ø 0.05 mm)		

Electrical connection - Socket		
Connector: 1 x M8, straight; coding: A; Moulded body: PUR		

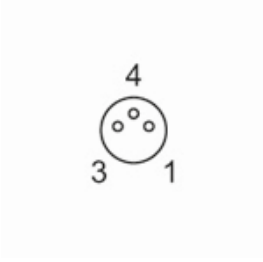


E10207



Female cordset

ADOGG030--S0002E03

Connection

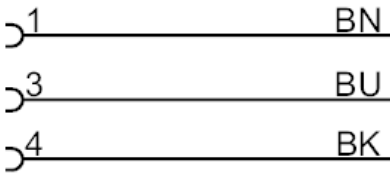

BN =	Core colors :	brown
BK =		black
BU =		blue