


E10212



Female cordset

ADOGA030MSS0005B03

Article no longer available - archive entry

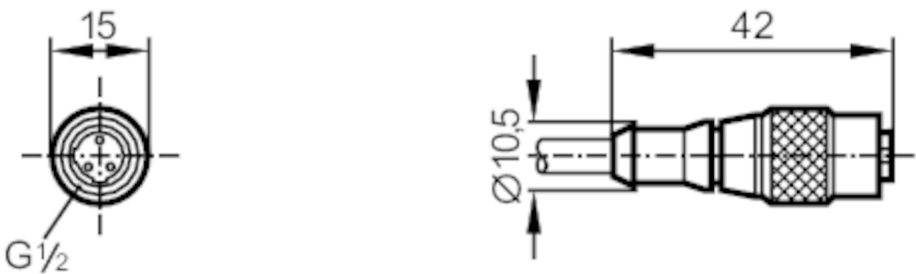

Electrical data		
Operating voltage	[M]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 42
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 5 m, PUR, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)		
Electrical connection - Socket		

Connector: 1 x 1/2", straight; coding: C; Moulded body: TPU (urethane); Locking: brass, nickel-plated




E10212



Female cordset

ADOGA030MSS0005B03

Connection

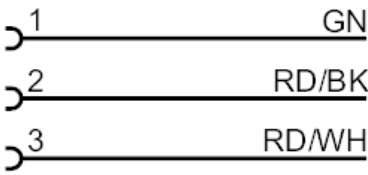

GN =	Core colors :
RD/BK =	green
RD/WH =	red/black
	red/white