


E10214



Female cordset

ADOAH040MSS0005A02

Article no longer available - archive entry

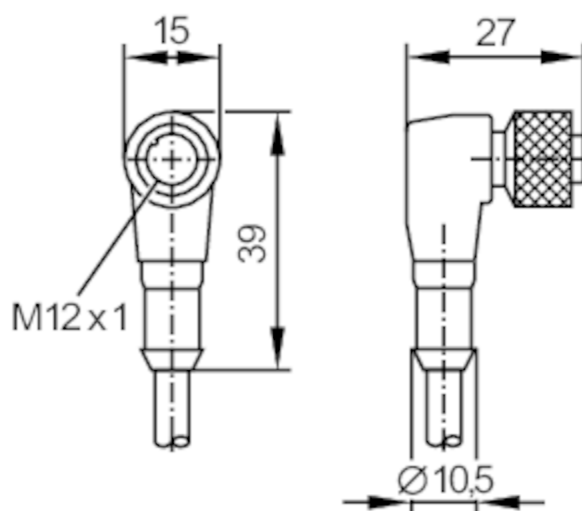

Electrical data

Operating voltage [V] < 250 AC / < 300 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 27 x 15 x 39

Material TPU (urethane)

Molded-body material TPU (urethane)

Material nut brass, nickel-plated

Remarks


Pack quantity 1 pcs.

Electrical connection

Cable: 5 m, PUR / PVC, orange, Ø 5 mm; 2 x 0.34 mm²

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

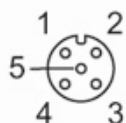


E10214



Female cordset

ADOAH040MSS0005A02

Connection

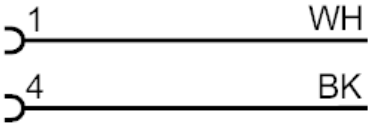

BK = Core colors :
WH = black
 white