


E10252



Female cordset

ADOGH040ZDS0005A03

Article no longer available - archive entry

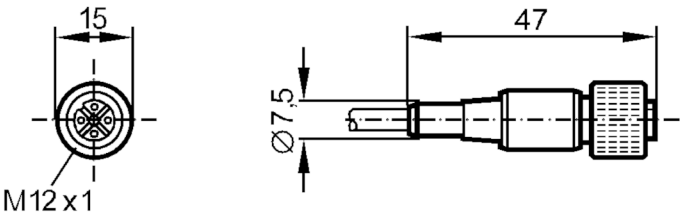

Electrical data

Operating voltage	[V]	< 250 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Dimensions	[mm]	15 x 15 x 47
Material		PUR
Molded-body material		PUR
Material nut		diecast zinc, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

Cable: 5 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.34 mm²

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated




E10252



Female cordset

ADOGH040ZDS0005A03

Connection

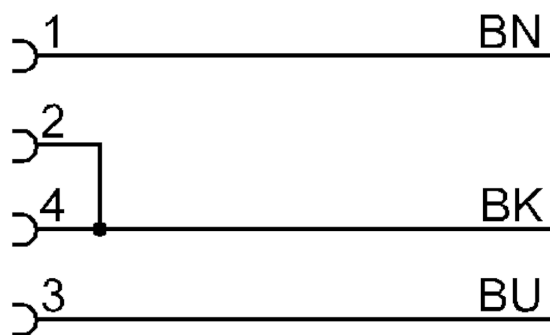

BN =
BK =
BU =

Core colors :
brown
black
blue