

E10255




Female cordset

ADOAH042ZDS0010A03

Article no longer available - archive entry

Alternative articles: EVC009
When selecting an alternative article and accessories please note that technical data may differ!

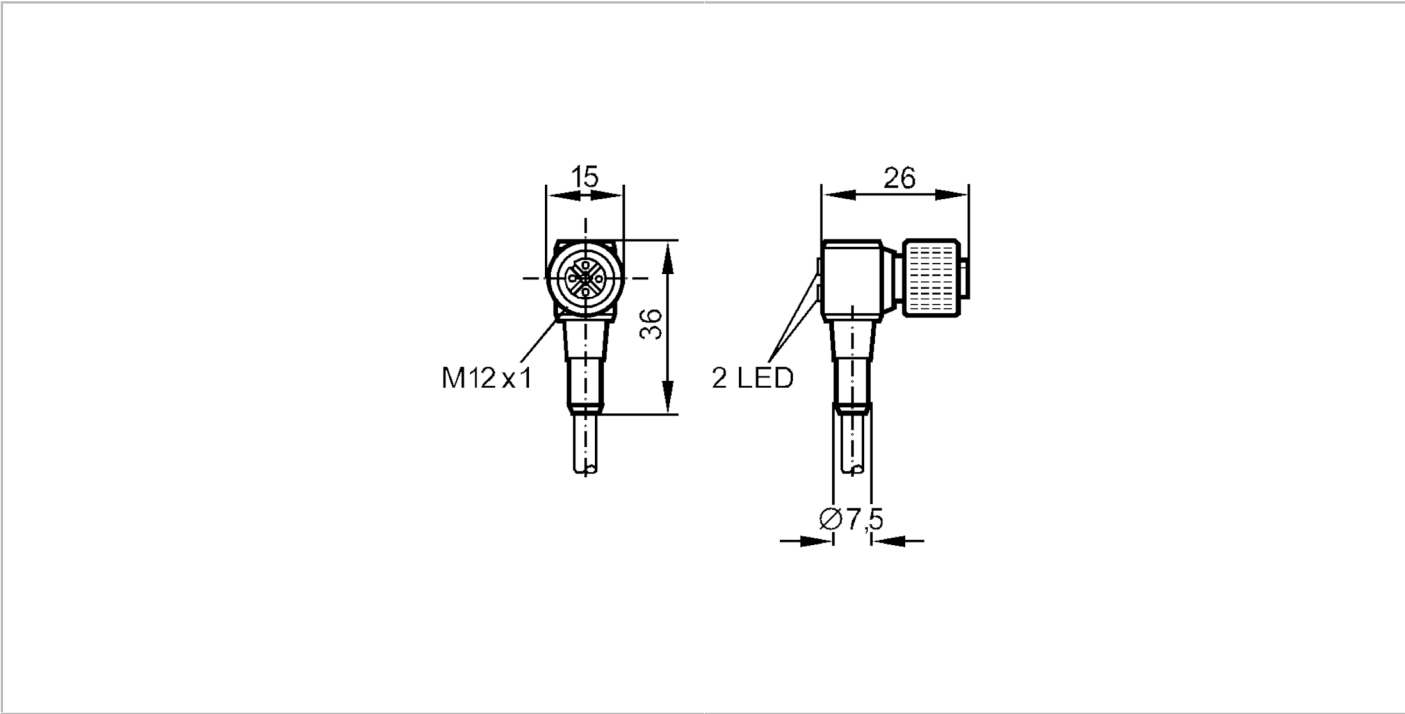

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Dimensions	[mm]	36 x 15 x 26
Material		PUR
Molded-body material		PUR
Material nut		diecast zinc, nickel-plated
Displays / operating elements		
Display	Switching status	1 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10255



Female cordset

ADOAH042ZDS0010A03

Electrical connection

Cable: 10 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated



Connection



BK = Core colors :
BN = black
BU = brown
blue