

E10259




Female wirable connectors

SDOGH040PLSFKPG

Article no longer available - archive entry

Alternative articles: E11508
When selecting an alternative article and accessories please note that technical data may differ!

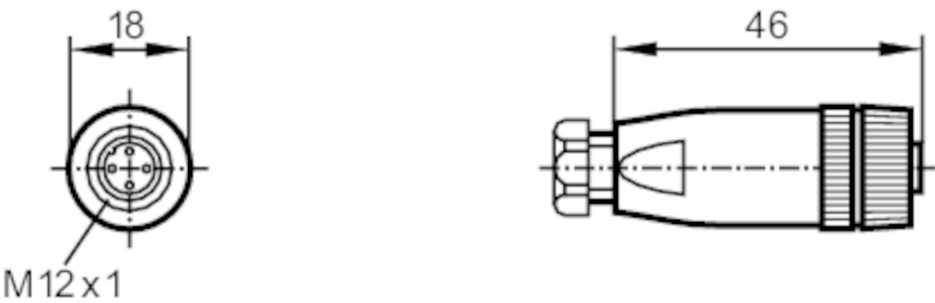

Electrical data		
Operating voltage	[V]	10...55 DC
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Dimensions	[mm]	18 x 18 x 46
Material		PBT
Molded-body material		PBT
Material nut		PA
Remarks		
Pack quantity		1 pcs.

E10259



Female wirable connectors

SDOGH040PLSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PBT; Locking: PA



Connection

