




Wiring block

ZDO4H055MSS0005H07

Article no longer available - archive entry

Alternative articles: EBC015
When selecting an alternative article and accessories please note that technical data may differ!

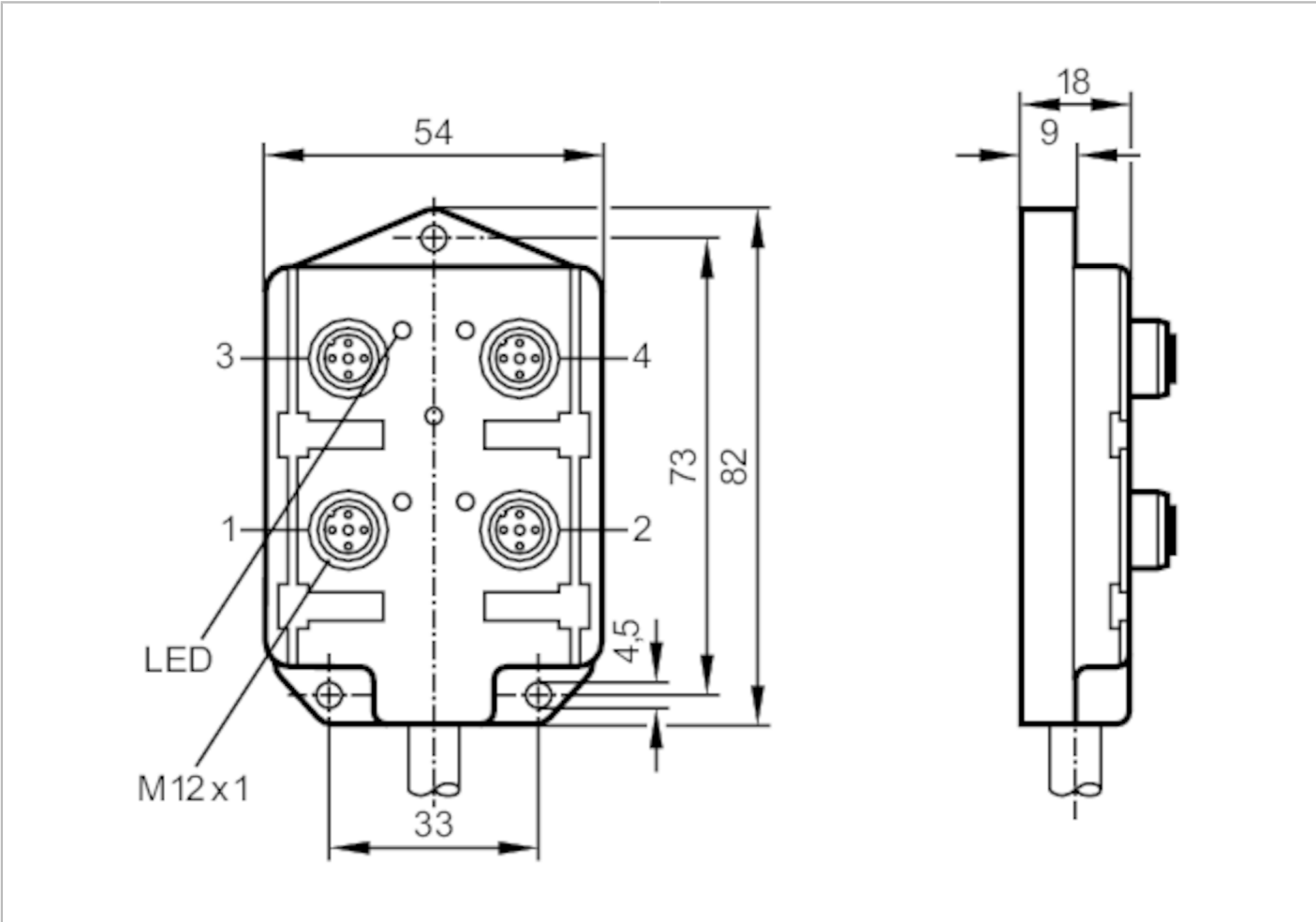

Application		
System	Free from silicone; Halogen-free; gold-plated contacts	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67
Mechanical data		
Dimensions	[mm]	18 x 54 x 82
Material		TPU (urethane)
Molded-body material		TPU (urethane)

E10278



Wiring block

ZDO4H055MSS0005H07

Number of ports splitter box	4
Connector type	M12

Displays / operating elements

Display	Switching status	4 x LED, yellow
	Power	1 x LED, green

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 8.4 mm; 4 x 0.34 mm² (43 x Ø 0.1 mm) + 3 x 0.75 mm² (95 x Ø 0.1 mm)

Electrical connection - slot

Connector: 4 x M12; coding: A; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm

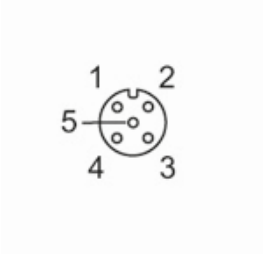


E10278



Wiring block

ZDO4H055MSS0005H07

Connection

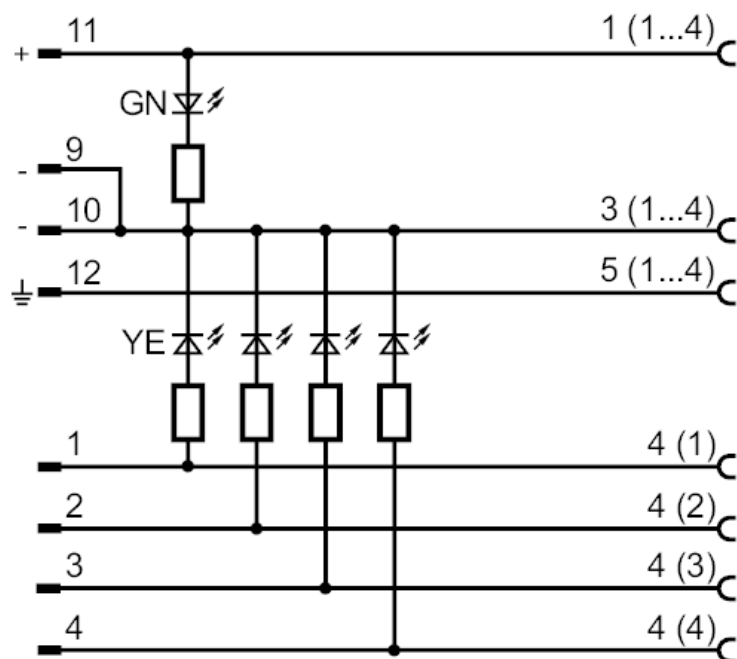

BN =
BU =
GN =
GN/YE =
GY =
WH =
YE =

Core colors :
brown
blue
green
green/yellow
grey
white
yellow