

E10280




Wiring block

ZDO6H057MSS0005H09

Article no longer available - archive entry

Alternative articles: EBC019
When selecting an alternative article and accessories please note that technical data may differ!

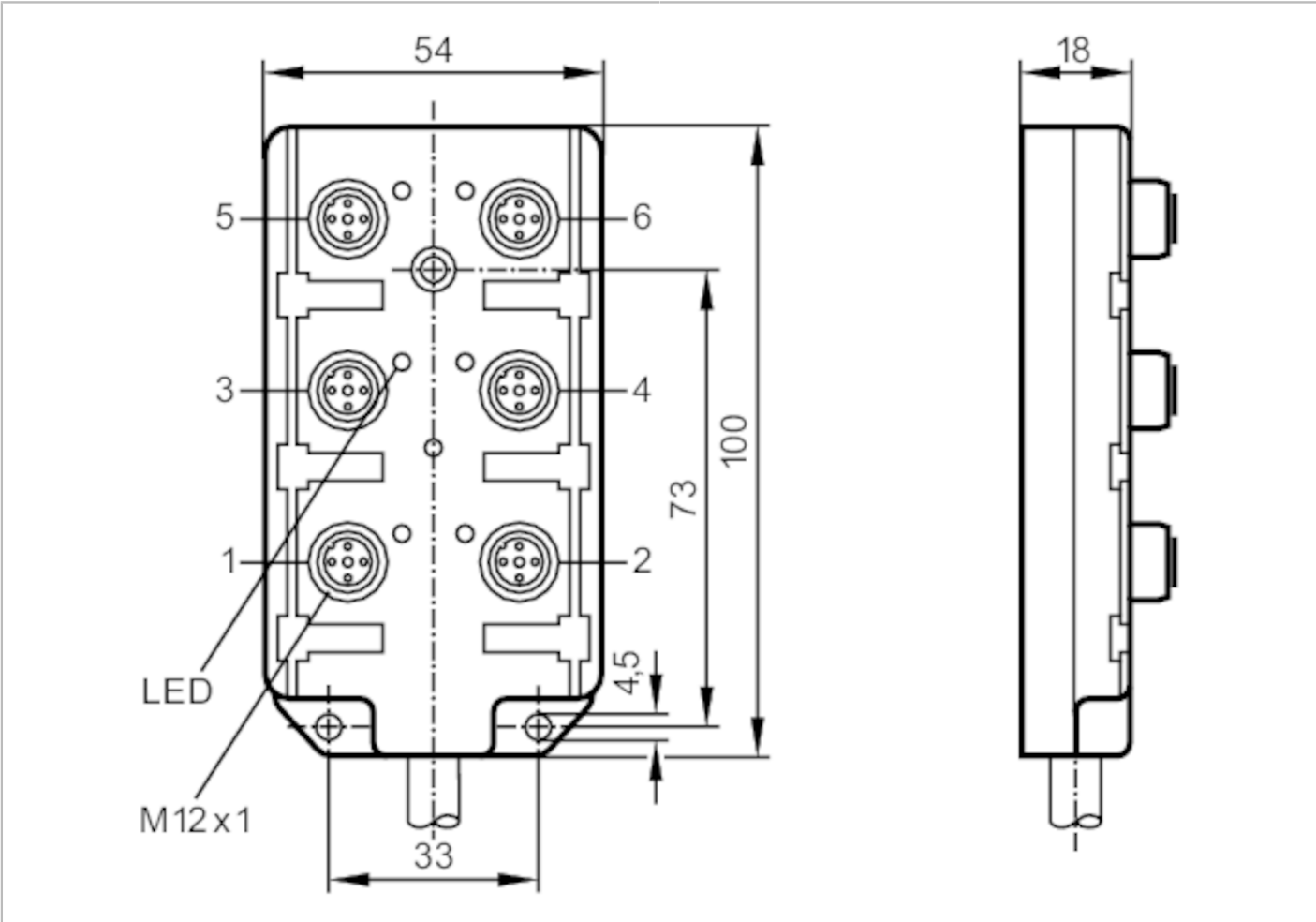

Application		
System		Free from silicone; Halogen-free; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67
Mechanical data		
Dimensions	[mm]	18 x 54 x 100
Material		TPU (urethane)
Molded-body material		TPU (urethane)

E10280



Wiring block

ZDO6H057MSS0005H09

Number of ports splitter box	6
Connector type	M12

Displays / operating elements

Display	Switching status	6 x LED, yellow
	Power	1 x LED, green

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 9 mm; 6 x 0.34 mm² (43 x Ø 0.1 mm) + 3 x 0.75 mm² (95 x Ø 0.1 mm)

Electrical connection - slot

Connector: 6 x M12; coding: A; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm

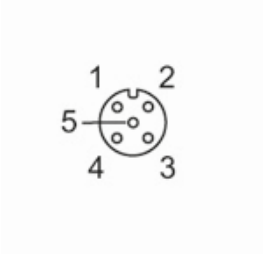


E10280



Wiring block

ZDO6H057MSS0005H09

Connection

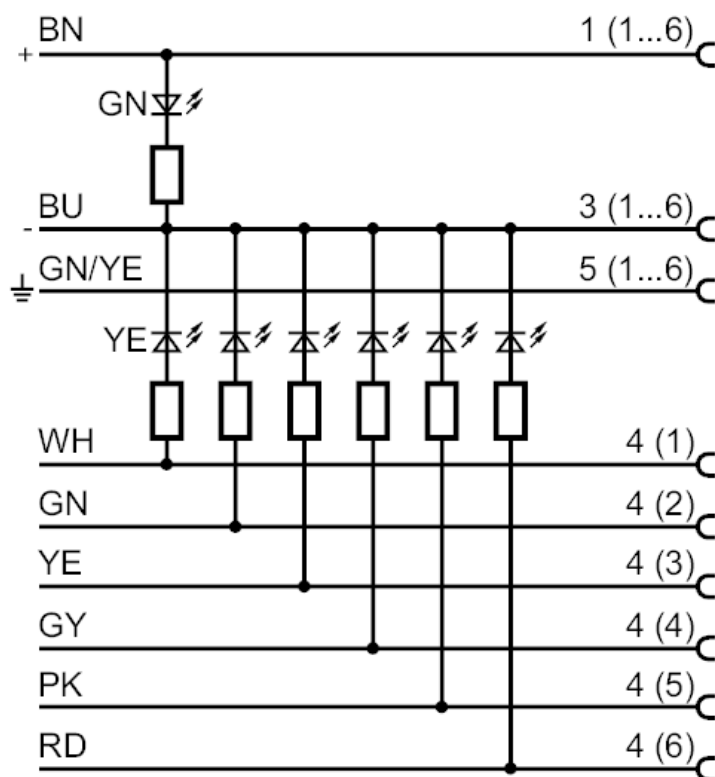

	Core colors :
BN =	brown
BU =	blue
GN =	green
GN/YE =	green/yellow
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow