

E10282




Wiring block

ZDO8H059MSS0005H11

Article no longer available - archive entry

Alternative articles: EBC023
When selecting an alternative article and accessories please note that technical data may differ!

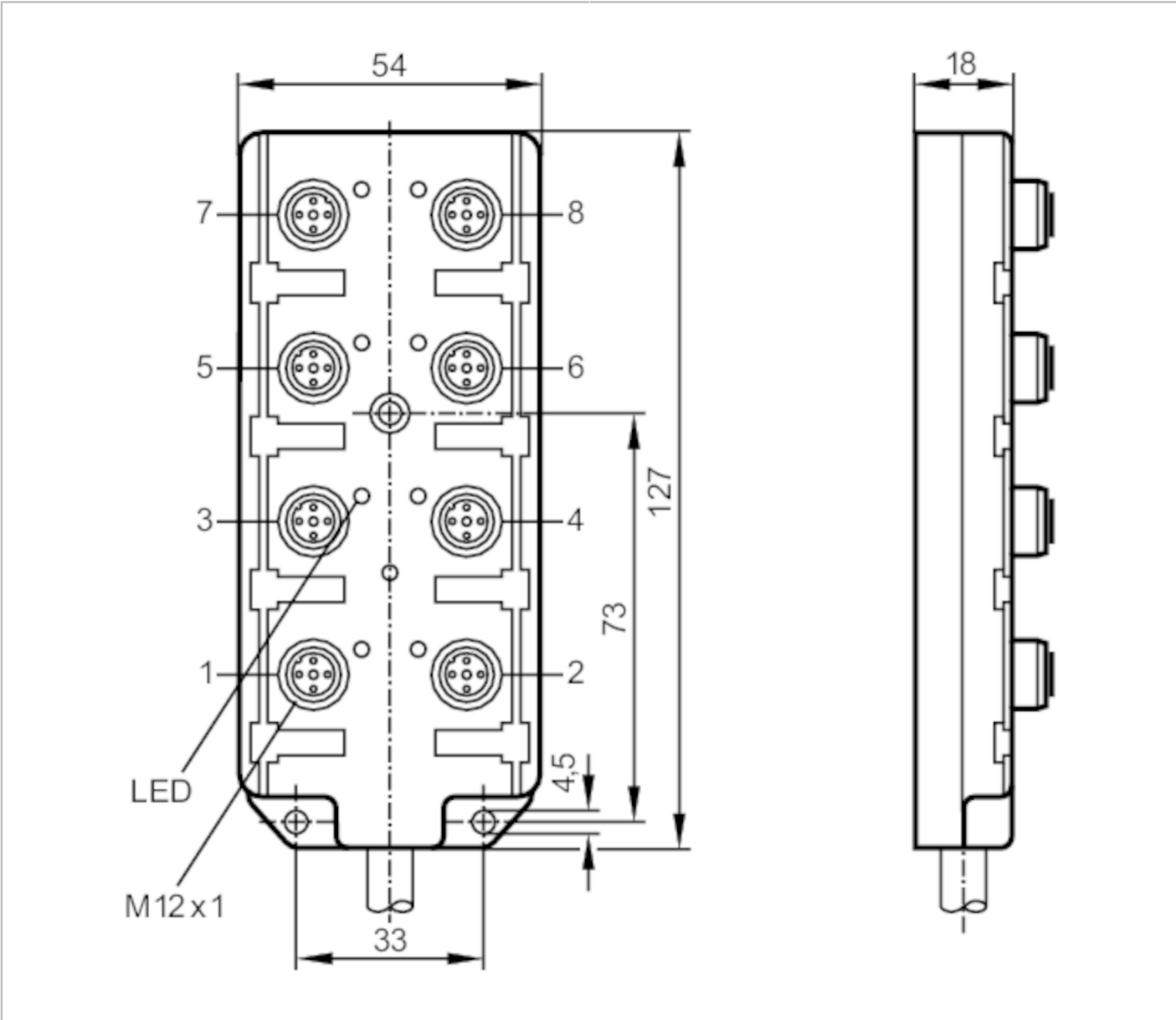

 
Application		
System		Free from silicone; Halogen-free; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

E10282



Wiring block

ZDO8H059MSS0005H11

Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67
Mechanical data		
Dimensions	[mm]	18 x 54 x 127
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Number of ports splitter box		8
Connector type		M12
Displays / operating elements		
Display	Switching status	8 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 5 m, PUR, Halogen-free, black, Ø 9 mm; 8 x 0.34 mm ² (43 x Ø 0.1 mm) + 3 x 0.75 mm ² (95 x Ø 0.1 mm)		
Electrical connection - slot		
Connector: 8 x M12; coding: A; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm		
		


E10282



Wiring block

ZDO8H059MSS0005H11

Connection

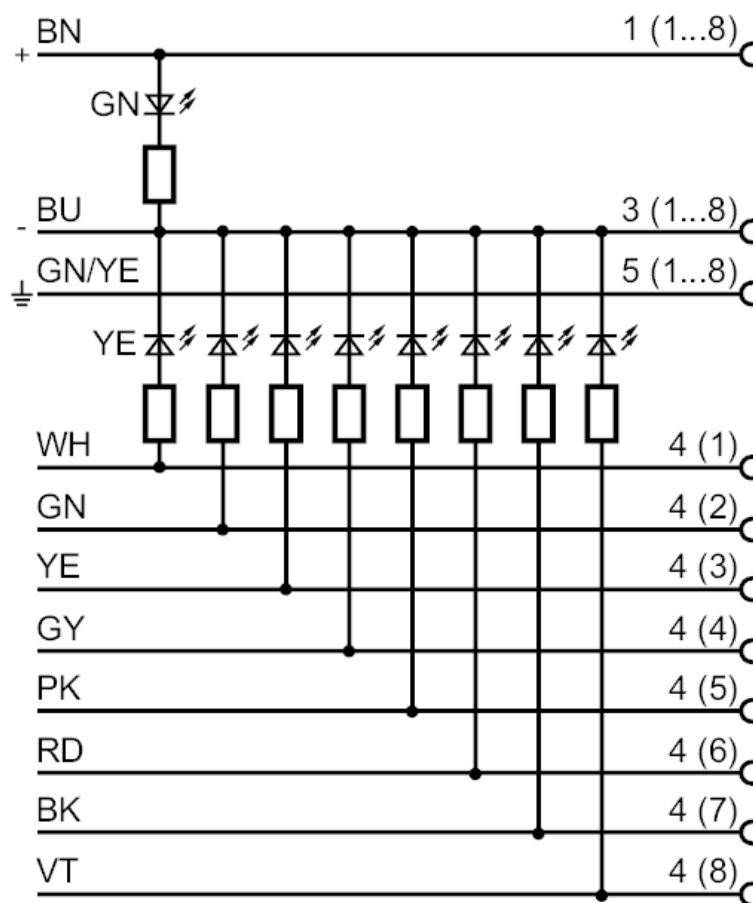

	Core colors :
BK =	black
BN =	brown
BU =	blue
GN =	green
GN/YE =	green/yellow
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white
YE =	yellow