


E10296



Female cordset

ADOAH040MSS0005F03

Article no longer available - archive entry

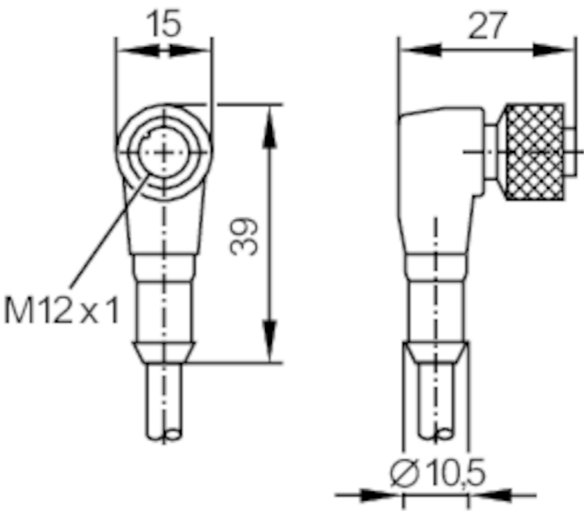

Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, weld coated
Remarks		
Pack quantity		1 pcs.

Electrical connection	
Cable: 5 m, PVC, orange, Ø 5 mm; cross-linked; 3 x 0.34 mm²	

Electrical connection - Socket	
Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, weld coated; Tightening torque: 0.5 Nm	




E10296



Female cordset

ADOAH040MSS0005F03

Connection

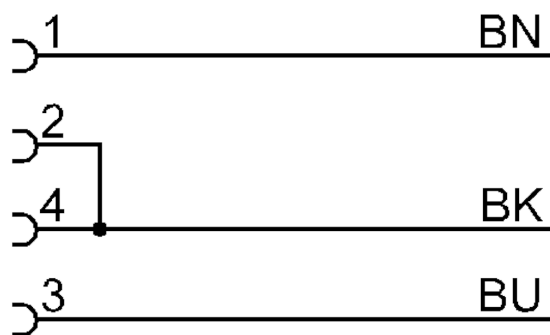

BN =
BK =
BU =

Core colors :
brown
black
blue