

E10305



Female cordset


ADOAH040MSS0005A04

Article no longer available - archive entry



Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 5 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm²		
Electrical connection - Socket		

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

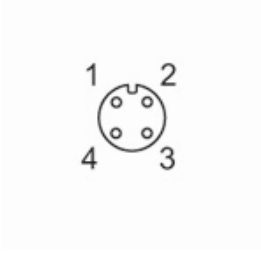


E10305



Female cordset

ADOAH040MSS0005A04

Connection

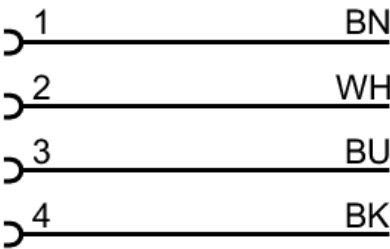

	Core colors :
BN =	brown
BK =	black
BU =	blue
WH =	white