


# E10334



## Female cordset


ADOAH040VAS0010E02

Article no longer available - archive entry

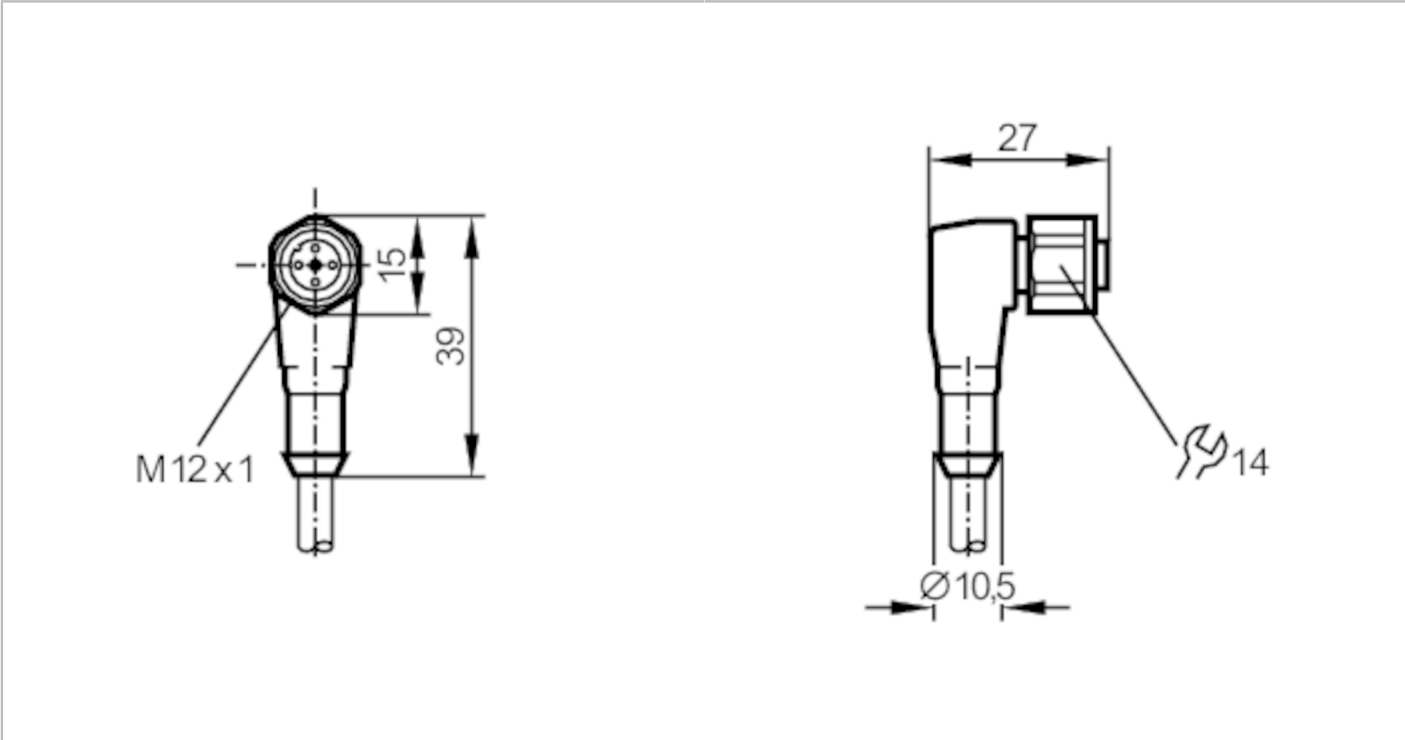

| Electrical data                                                 |      |                                 |
|-----------------------------------------------------------------|------|---------------------------------|
| Operating voltage                                               | [M]  | < 250 AC / < 300 DC             |
| Operating conditions                                            |      |                                 |
| Ambient temperature                                             | [°C] | -25...90                        |
| Protection                                                      |      | IP 67                           |
| Mechanical data                                                 |      |                                 |
| Dimensions                                                      | [mm] | 27 x 15 x 39                    |
| Material                                                        |      | TPU (urethane)                  |
| Molded-body material                                            |      | TPU (urethane)                  |
| Material nut                                                    |      | stainless steel (1.4404 / 316L) |
| Remarks                                                         |      |                                 |
| Pack quantity                                                   |      | 1 pcs.                          |
| Electrical connection                                           |      |                                 |
| Cable: 10 m, PVC, orange, Ø 5 mm; 2 x 0.34 mm² (42 x Ø 0.1 mm ) |      |                                 |
| Electrical connection - Socket                                  |      |                                 |

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: stainless steel (1.4404 / 316L)

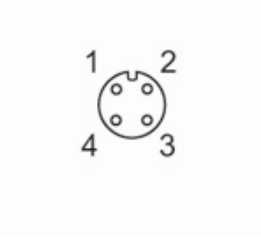


E10334



Female cordset

ADOAH040VAS0010E02

Connection

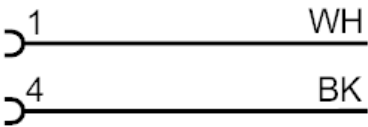

BK =  
WH =

Core colors :  
black  
white