

E10346




Wirable plug

SSTA040MSSFKPG

Article no longer available - archive entry

Alternative articles: E11505
When selecting an alternative article and accessories please note that technical data may differ!

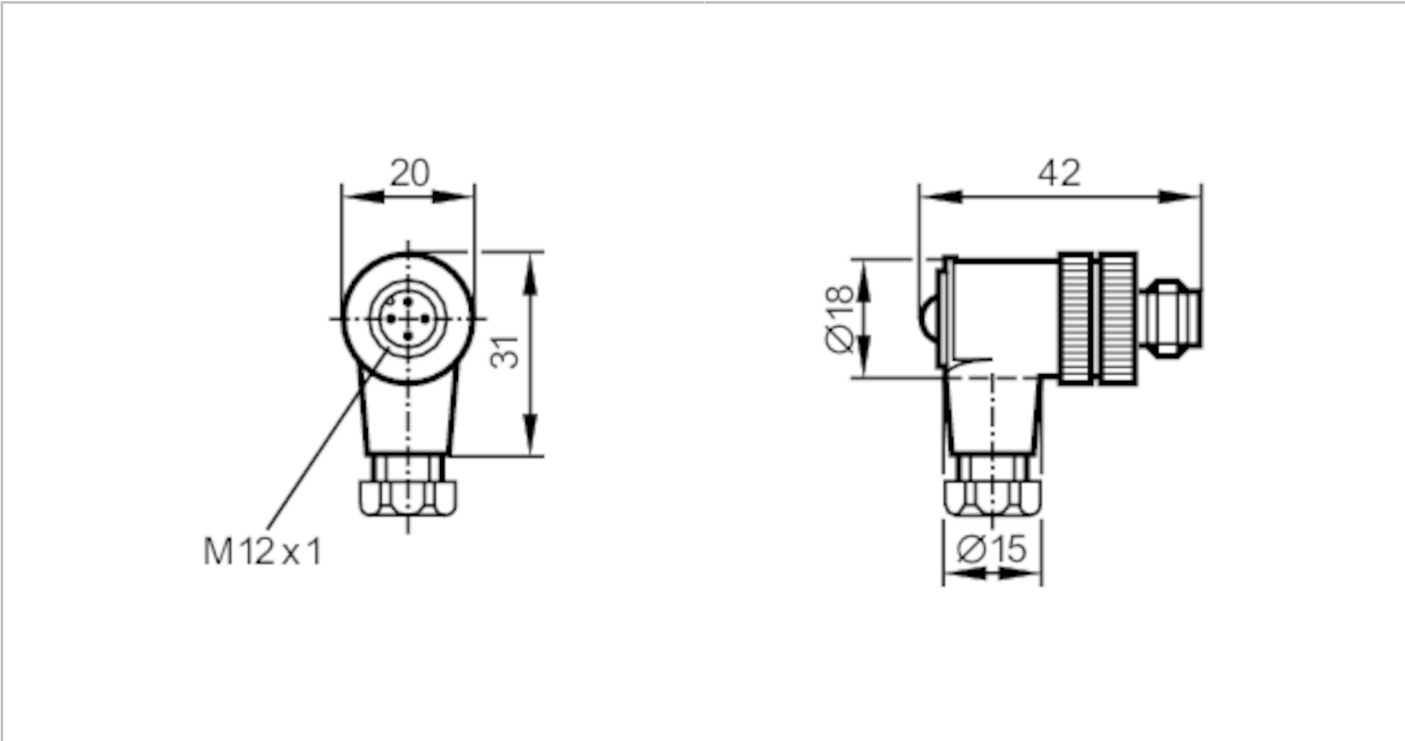

Electrical data		
Operating voltage	[V]	< 125 AC / < 150 DC
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Material		PBT
Molded-body material		PBT
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
terminals: ...0.5 mm²; Cable sheath: Ø 4...6 mm		
Electrical connection - plug		
Connector: 1 x M12, angled; Moulded body: PBT; Locking: brass, nickel-plated		

E10346



Wirable plug

SSTA040MSSFKPG



Connection

