

# E10347




## Connection cable

VDOAF032MSS00,6A03STGH030MSS

Article no longer available - archive entry

Alternative articles: E11387  
When selecting an alternative article and accessories please note that technical data may differ!

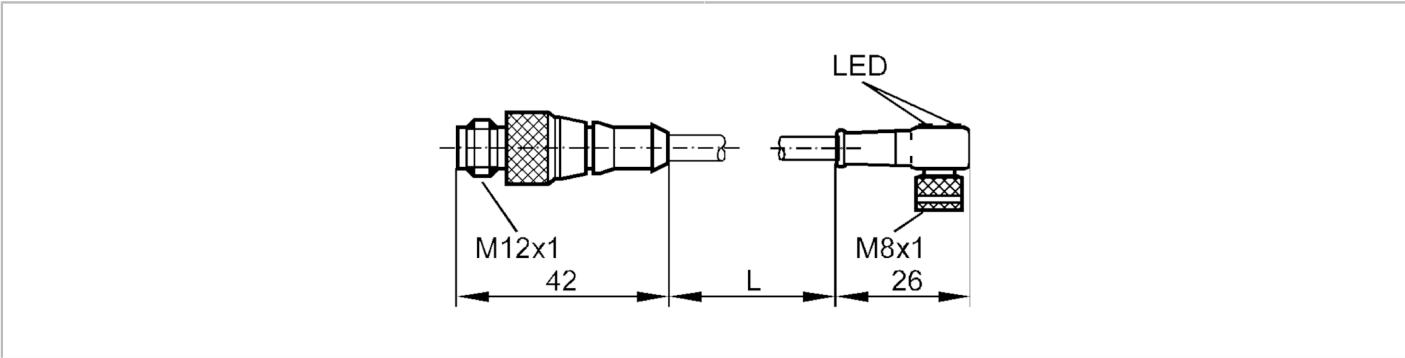

### Electrical data

|                   |     |            |
|-------------------|-----|------------|
| Operating voltage | [V] | 10...30 DC |
| Protection class  |     | III        |

### Outputs

|                   |     |
|-------------------|-----|
| Electrical design | PNP |
|-------------------|-----|

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection          |      | IP 67    |

### Mechanical data

|                      |                      |
|----------------------|----------------------|
| Material             | PUR                  |
| Molded-body material | PUR                  |
| Material nut         | brass, nickel-plated |

### Displays / operating elements


|         |                  |                 |
|---------|------------------|-----------------|
| Display | Switching status | 1 x LED, yellow |
|         | Power            | 1 x LED, green  |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

### Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated

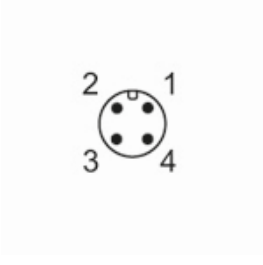

# E10347



## Connection cable

VDOAF032MSS00,6A03STGH030MSS

### Electrical connection

Cable: 0.6 m, PUR / PVC; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

#### Connection



### Electrical connection - Buchse



#### Connection



### Electrical connection - Socket

Connector: 1 x M8, angled; Moulded body: PUR; Locking: brass, nickel-plated