

E10357




Female cordset

ADOGH040MSN0002A04

Article no longer available - archive entry

Alternative articles: ENC01A

When selecting an alternative article and accessories please note that technical data may differ!

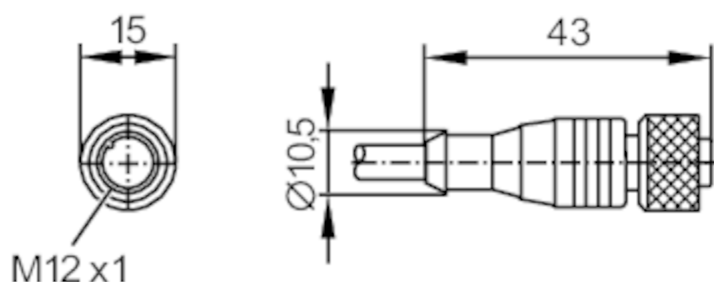

Application

Application Ex zone 1

Electrical data

Operating voltage [V] < 15 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Safety classification

Max. internal capacitance [nF] 0.196

Max. internal inductance [µH] 4

Mechanical data

Dimensions [mm] 15 x 15 x 43

Material TPU (urethane) blue

Molded-body material TPU (urethane), blue

Material nut brass, nickel-plated

Remarks

Remarks When using sockets in hazardous areas (ATEX) there are special requirements regarding wiring.
The requirements of the applicable installation regulations must be absolutely adhered to by the user on his own responsibility.

Pack quantity 1 pcs.

E10357



Female cordset


ADOGH040MSN0002A04

Electrical connection


Cable: 2 m, PUR / PVC, blue, Ø 5 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane), blue; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

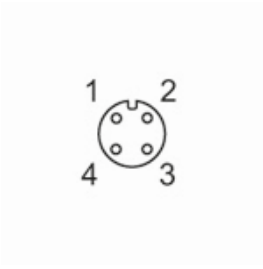

Connection

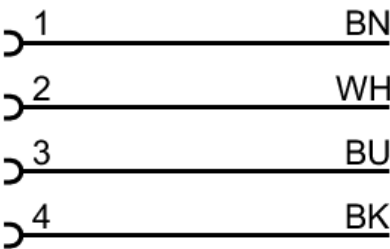

	Core colors :
BK =	black
BN =	brown
BU =	blue
WH =	white