


E10359



Female cordset

AD0GB030PLS0010E03


Article no longer available - archive entry

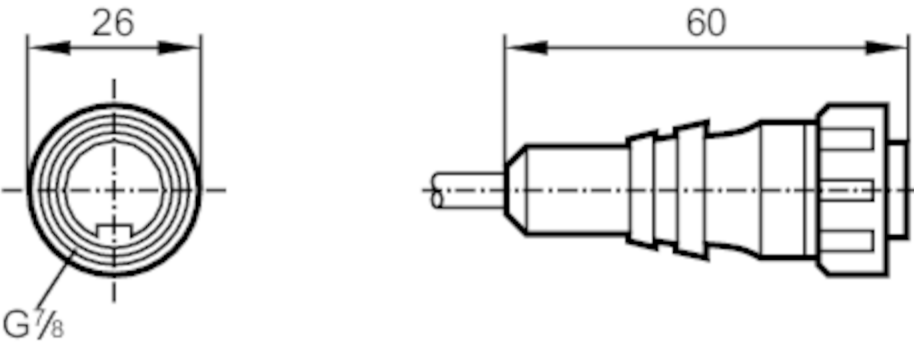

Electrical data		
Operating voltage	[M]	< 250 AC
Operating conditions		
Ambient temperature	[°C]	-40...90
Protection		IP 68
Mechanical data		
Dimensions	[mm]	26 x 26 x 60
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		PA 6 GV
Remarks		
Pack quantity		1 pcs.

Electrical connection	
Cable: 10 m, PVC, orange, Ø 7.2 mm; 3 x 0.75 mm² (22 x Ø 0.2 mm)	

Electrical connection - Socket	
Connector: 1 x 7/8", straight; coding: A; Moulded body: TPU (urethane); Locking: PA 6 GV	

 


E10359



Female cordset

ADOGB030PLS0010E03

Connection

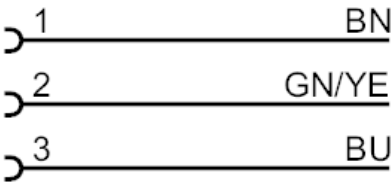

BN =	Core colors :	brown
BU =		blue
GN/YE =		green/yellow