

E10394



Female cordset


ADOGH040MSS0010A02

Article no longer available - archive entry



Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 43
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 10 m, PUR / PVC, orange, Ø 5 mm; 2 x 0.34 mm² (180 x Ø 0.05 mm)		
Electrical connection - Socket		

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

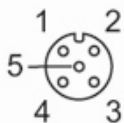


E10394



Female cordset

ADOGH040MSS0010A02

Connection

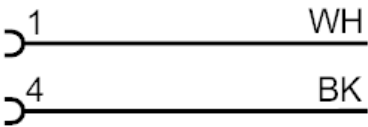

BK = Core colors :
WH = black
 white