

E10395




Connection cable

VDOAH042MSS00,6A04STAH040MSS

Article no longer available - archive entry

Alternative articles: EVC036

When selecting an alternative article and accessories please note that technical data may differ!

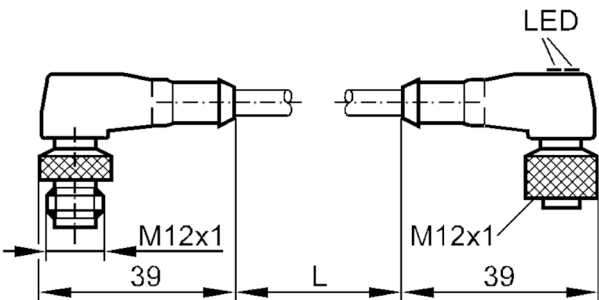

Electrical data

Operating voltage [V] 10...30 DC

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Material PUR

Molded-body material PUR

Material nut brass, nickel-plated

Displays / operating elements

Display	Switching status	1 x LED, yellow
	Power	1 x LED, green

Remarks

Pack quantity 1 pcs.

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



E10395




Connection cable

VDOAH042MSS00,6A04STAH040MSS

Electrical connection

Cable: 0.6 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Connection

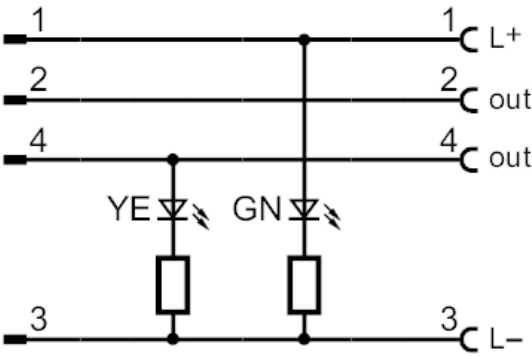

	Core colors :
BK =	black
BN =	brown
BU =	blue
GN =	green
WH =	white
YE =	yellow

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated

