


E11425



Patchcords with valve plug

VVDAB031MSS0005H03STGH030MSS

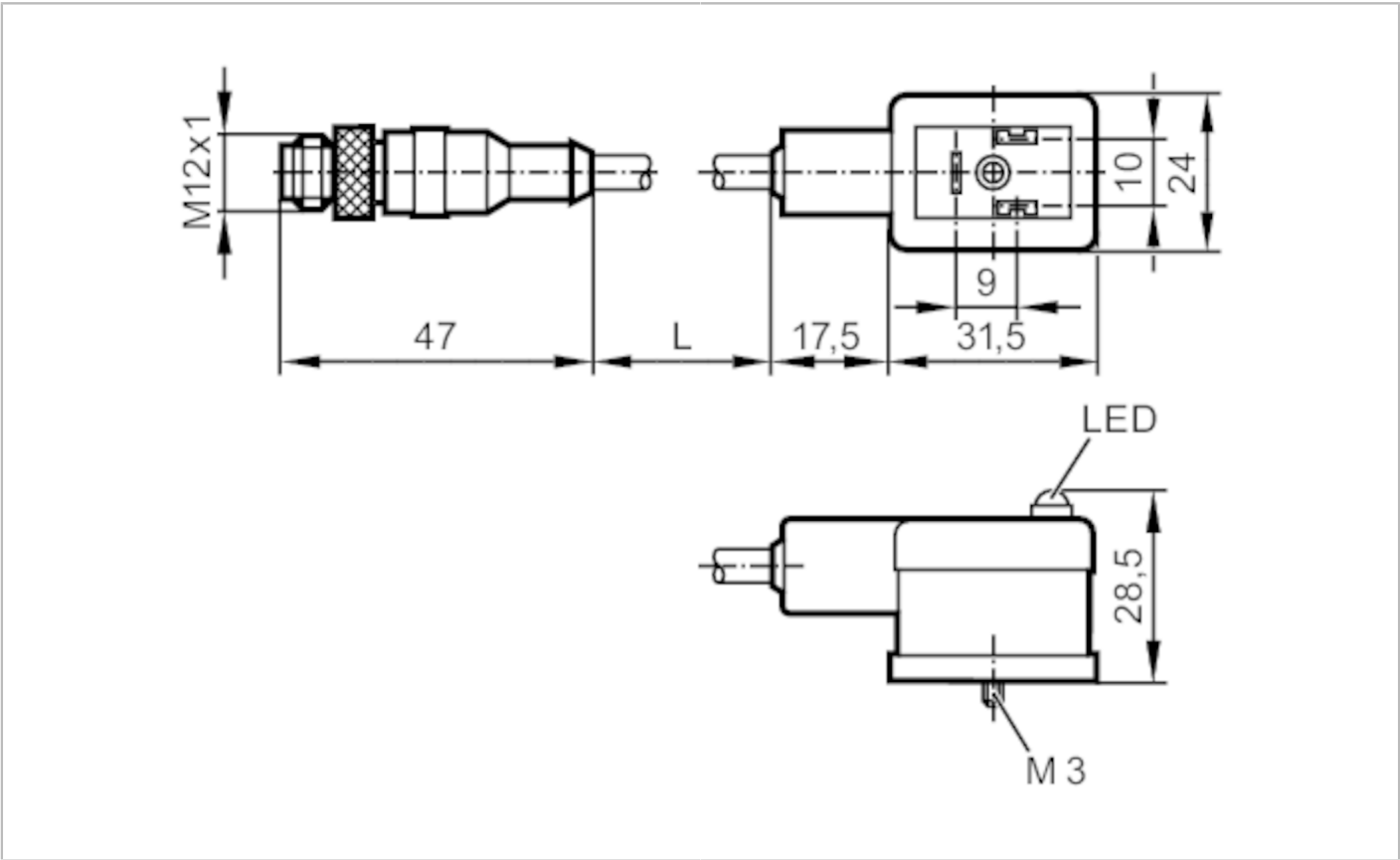

Application

System	Free from silicone; Halogen-free; gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage [V]	< 24 AC/DC
Overvoltage protection	yes; (VDR)
Max. current load total [A]	3

Operating conditions

Ambient temperature [°C]	-25...80
Protection	IP 67

Mechanical data

Weight [g]	267.7
Material	PUR
Molded-body material	PUR
Material nut	brass, nickel-plated

Displays / operating elements

Display	Power	1 x LED, yellow
---------	-------	-----------------

Accessories

Items supplied	screw
	panel for labelling

E11425



Patchcords with valve plug


VVDAB031MSS0005H03STGH030MSS

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

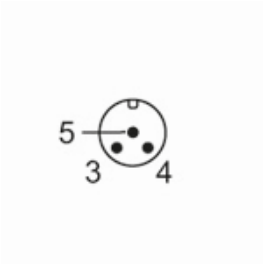

Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 5 mm; 3 x 0.5 mm² (42 x Ø 0.1 mm)

Connection

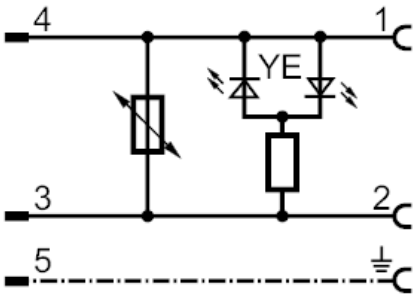

Electrical connection - Socket

Connector: 1 x valve type B DIN, angled; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: nickel-plated brass; Tightening torque: 0.7...0.9 Nm

