


E11436



Patchcords with valve plug

VVSAC031MSS00,3H03STGH030MSS

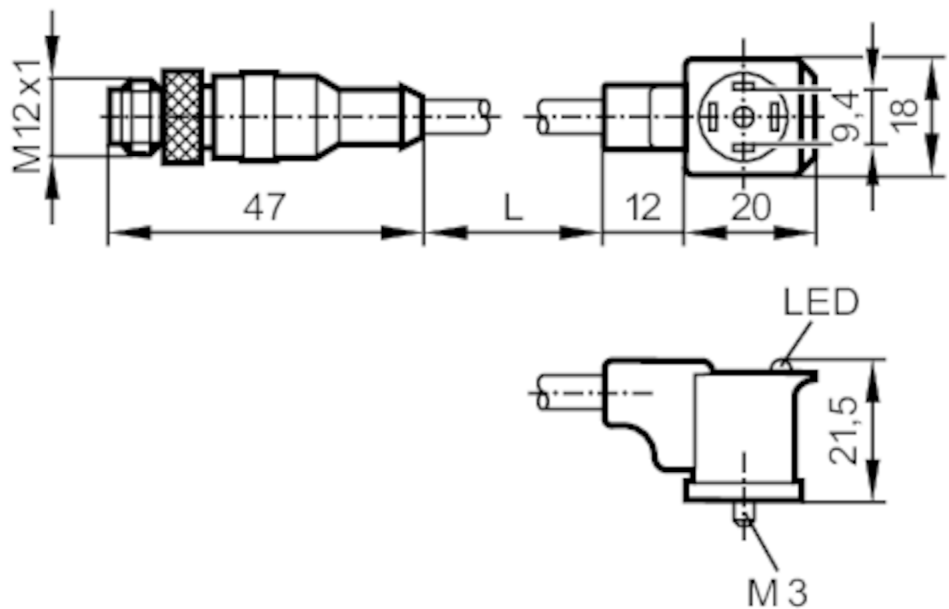

Application		
System	Free from silicone; Halogen-free; gold-plated contacts	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	< 24 AC/DC
Overvoltage protection	yes; (VDR)	
Max. current load total	[A]	3
Operating conditions		
Ambient temperature	[°C]	-25...80
Protection	IP 67	
Mechanical data		
Weight	[g]	44.5
Material	PUR	
Molded-body material	PUR	
Material nut	brass, nickel-plated	
Displays / operating elements		
Display	Switching status	1 x LED, yellow
Accessories		
Items supplied	screw	
	panel for labelling	
Remarks		
Pack quantity	1 pcs.	

E11436



Patchcords with valve plug

VVSAC031MSS00,3H03STGH030MSS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 5 mm; 3 x 0.5 mm² (42 x Ø 0.1 mm)

Connection

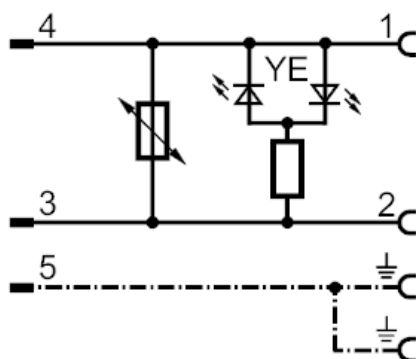

Electrical connection - Socket

Connector: 1 x valve type C industrial standard, angled; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: nickel-plated brass; Tightening torque: 0.7...0.9 Nm

