

# E11451




## Connection cable

VDOGH040MSS00,3H04STGH040MSS

Article no longer available - archive entry

Alternative articles: EVC013  
When selecting an alternative article and accessories please note that technical data may differ!

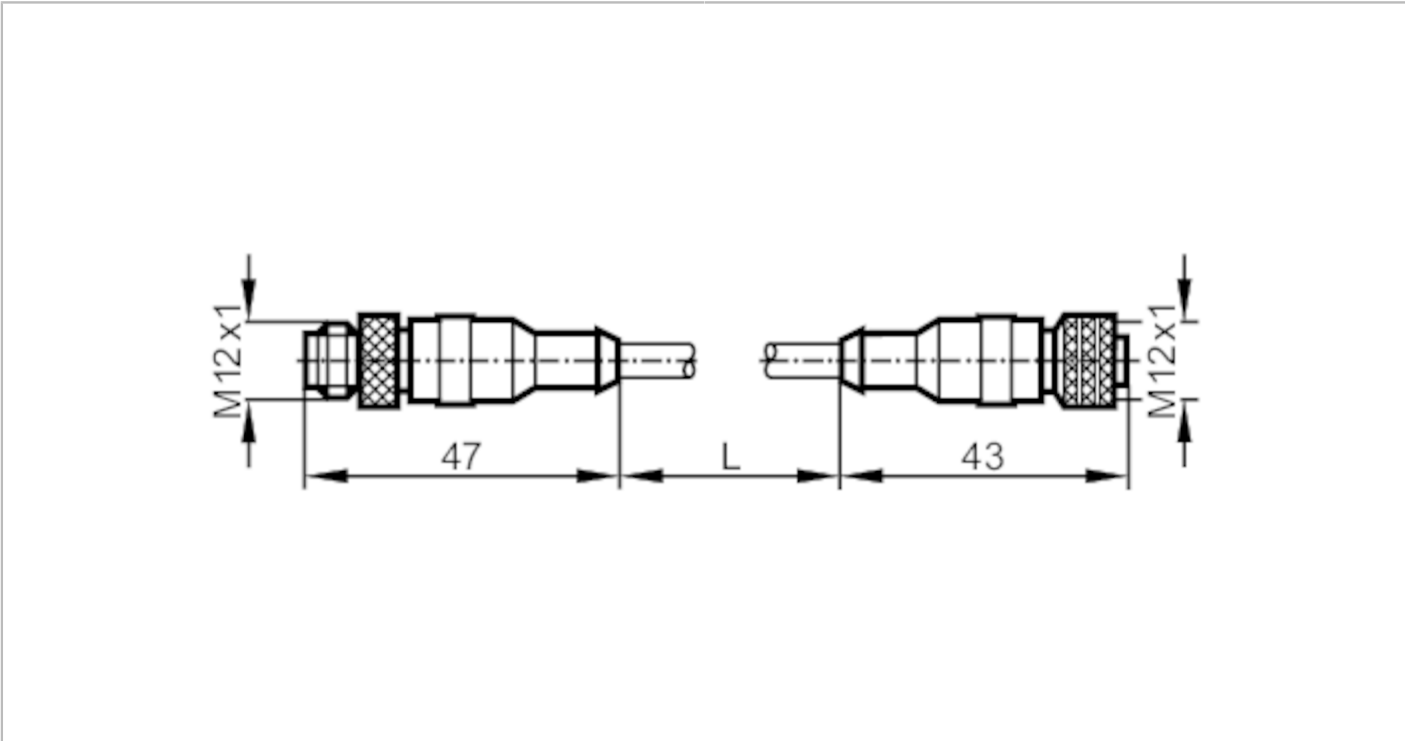

| Application             |      |                                                        |
|-------------------------|------|--------------------------------------------------------|
| System                  |      | Free from silicone; Halogen-free; gold-plated contacts |
| Free from silicone      |      | yes                                                    |
| Electrical data         |      |                                                        |
| Operating voltage       | [V]  | < 250 AC / < 300 DC                                    |
| Max. current load total | [A]  | 3                                                      |
| Operating conditions    |      |                                                        |
| Ambient temperature     | [°C] | -25...85                                               |
| Protection              |      | IP 68                                                  |
| Mechanical data         |      |                                                        |
| Material                |      | PUR                                                    |
| Molded-body material    |      | PUR                                                    |
| Material nut            |      | brass, nickel-plated                                   |
| Remarks                 |      |                                                        |
| Pack quantity           |      | 1 pcs.                                                 |

# E11451



## Connection cable

VDOGH040MSS00,3H04STGH040MSS

### Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



### Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 4.7 mm; 4 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Connection

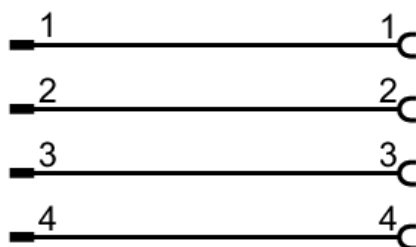

### Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

