


E11453



Connection cable

VDOGH040MSS0001H04STGH040MSS

Article no longer available - archive entry

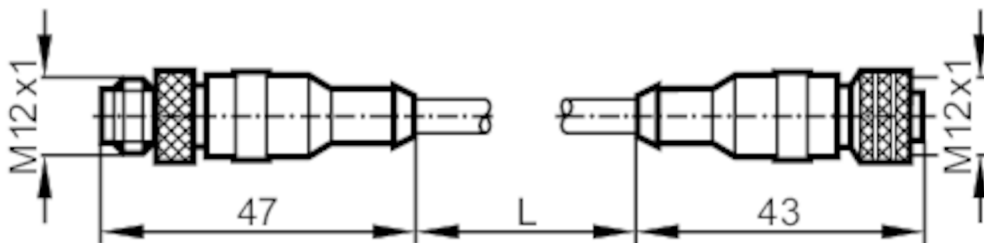


Application	
System	Free from silicone; gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 250 AC / < 300 DC
Max. current load total [A]	3
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 68
Mechanical data	
Material	PUR
Material nut	brass, nickel-plated / brass, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection - plug	
Connector: 1 x M12, straight; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm	

E11453



Connection cable

 
VDOGH040MSS0001H04STGH040MSS



Electrical connection


Cable: 1 m, PUR, black, Ø 4.7 mm; 4 x 0.34 mm² (4 x Ø 0.1 mm)

Connection

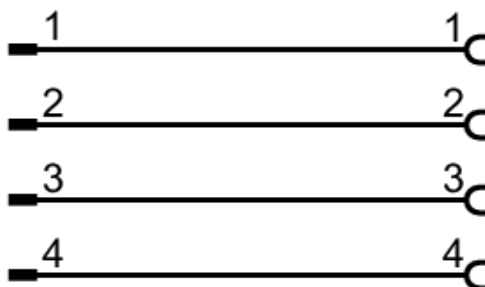

Electrical connection - Socket

 Connector: 1 x M12, straight; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



Article no longer available - archive entry