


Connection cable

VDOAH043MSS00,6H04STAH040MSS

Article no longer available - archive entry

Alternative articles: EVC036

When selecting an alternative article and accessories please note that technical data may differ!

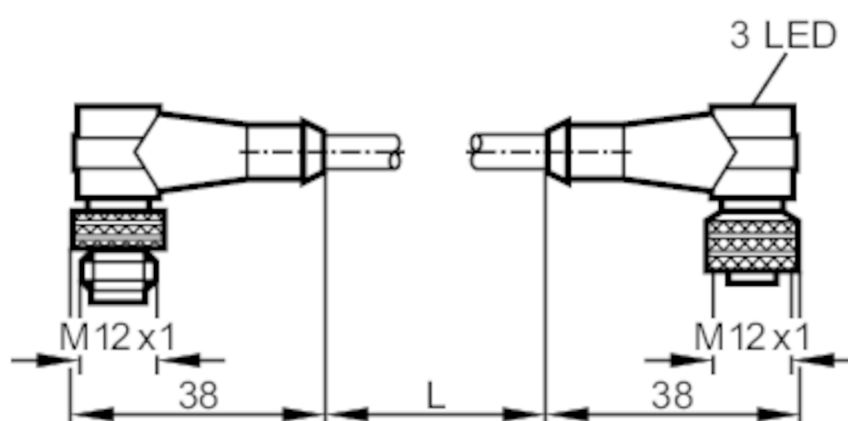

Application

System	Free from silicone; Halogen-free; gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...30 DC
Max. current load total	[A]	3

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 68

Mechanical data

Material	PUR
Molded-body material	PUR
Material nut	brass, nickel-plated

Displays / operating elements

Display	Switching status	2 x LED, yellow
	Power	1 x LED, green

E11477



Connection cable

VDOAH043MSS00,6H04STAH040MSS

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 0.6 m, PUR, Halogen-free, black, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)


Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

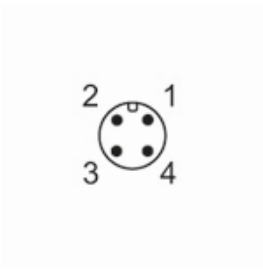

Electrical connection

Connection

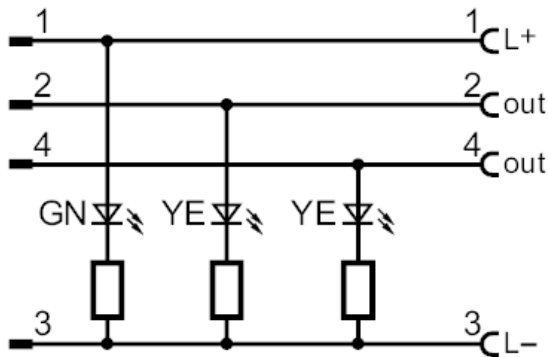

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

