

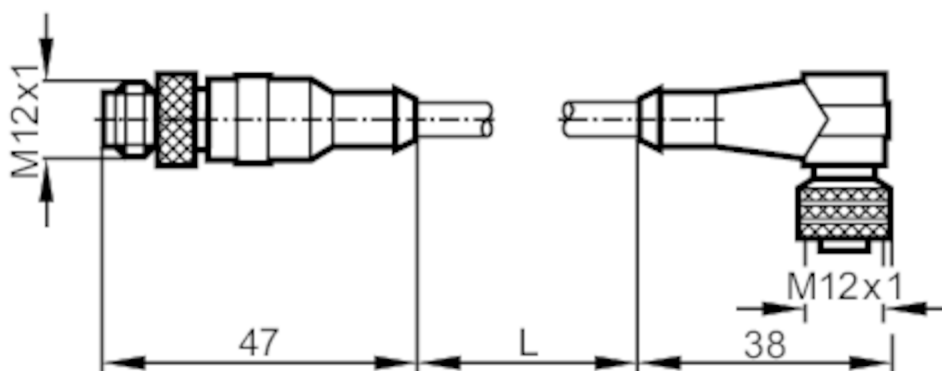
E11482



Connection cable

VDOAH050MSS00,6H05STGH050MSS

Article no longer available - archive entry



Application

System	Free from silicone; Halogen-free; gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load total	[A]	3

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 68

Mechanical data

Material	PUR
Molded-body material	PUR
Material nut	brass, nickel-plated

Remarks

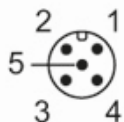
Pack quantity	1 pcs.
---------------	--------

**Connection cable**

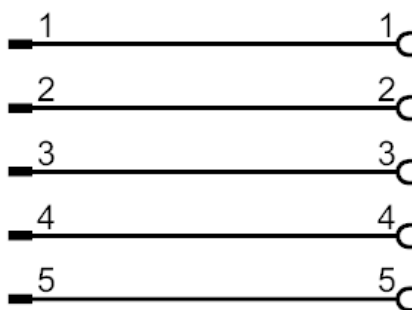
VDOAH050MSS00,6H05STGH050MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

**Electrical connection**

Cable: 0.6 m, PUR, Halogen-free, black, Ø 5 mm; 5 x 0.34 mm² (32 x Ø 0.1 mm)

Connection**Electrical connection - Socket**

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

