

E11489




Female cordset

ADOAF030MSS0002H03

Article no longer available - archive entry

Alternative articles: EVC144

When selecting an alternative article and accessories please note that technical data may differ!

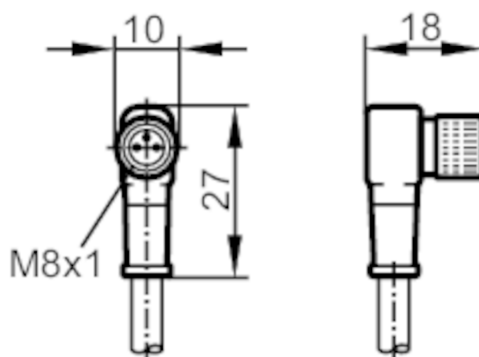

Application	
System	Free from silicone; Halogen-free; gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III
Max. current load total [A]	3
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 68
Mechanical data	
Dimensions [mm]	18 x 10 x 27
Material	PUR
Molded-body material	PUR
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

E11489



Female cordset

ADOAF030MSS0002H03

 
Electrical connection

Cable: 2 m, PUR, Halogen-free, black, Ø 4.1 mm; 3 x 0.25 mm² (32 x Ø 0.1 mm)


Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Connection

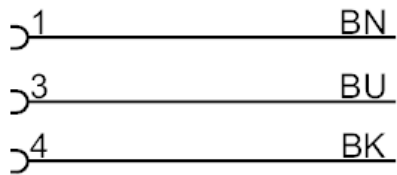

BK =	Core colors :
BN =	black
BU =	brown
	blue