


E11490



Female cordset

ADOAF030MSS0005H03

Article no longer available - archive entry

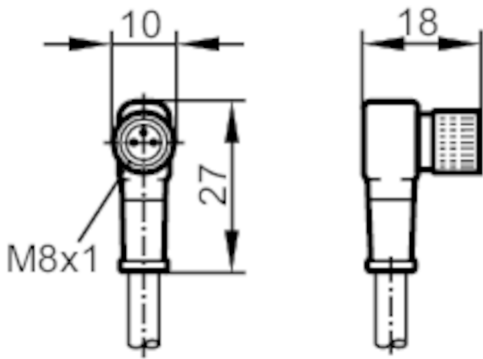

Application		
System		Free from silicone; Halogen-free; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III
Max. current load total	[A]	3
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 68
Mechanical data		
Dimensions	[mm]	18 x 10 x 27
Material		PUR
Molded-body material		PUR
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E11490



Female cordset

ADOAF030MSS0005H03

 
Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 4.1 mm; 3 x 0.25 mm² (32 x Ø 0.1 mm)


Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Connection

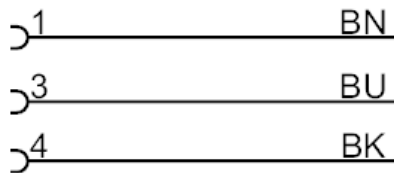

BK =	Core colors :
BN =	black
BU =	brown
	blue