

# E11492



## Female cordset

ADOAF032MSS0002H03

Article no longer available - archive entry

Alternative articles: EVC147  
When selecting an alternative article and accessories please note that technical data may differ!



| Application             |      |                                                        |
|-------------------------|------|--------------------------------------------------------|
| System                  |      | Free from silicone; Halogen-free; gold-plated contacts |
| Free from silicone      |      | yes                                                    |
| Electrical data         |      |                                                        |
| Operating voltage       | [V]  | 10...30 DC                                             |
| Protection class        |      | III                                                    |
| Max. current load total | [A]  | 3                                                      |
| Outputs                 |      |                                                        |
| Electrical design       |      | PNP                                                    |
| Operating conditions    |      |                                                        |
| Ambient temperature     | [°C] | -25...85                                               |
| Protection              |      | IP 68                                                  |
| Mechanical data         |      |                                                        |
| Dimensions              | [mm] | 17 x 10 x 26                                           |
| Material                |      | PUR                                                    |
| Molded-body material    |      | PUR                                                    |
| Material nut            |      | brass, nickel-plated                                   |

E11492



Female cordset

ADOAF032MSS0002H03

Displays / operating elements

|         |                  |                 |
|---------|------------------|-----------------|
| Display | Switching status | 1 x LED, yellow |
|         | Power            | 1 x LED, green  |

Remarks

 
|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

Electrical connection


Cable: 2 m, PUR, Halogen-free, black, Ø 4.1 mm; 3 x 0.25 mm² (32 x Ø 0.1 mm )

Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm  
Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Connection

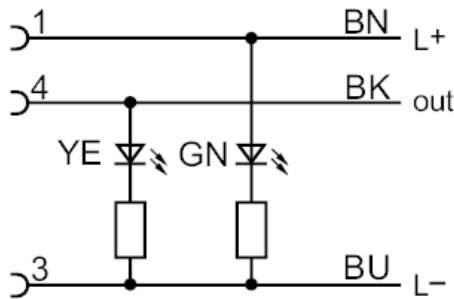

BK = Core colors :  
BN = black  
BU = brown  
blue