


E11500



Female cordset

ADOAF030VAS0025E03

Article no longer available - archive entry

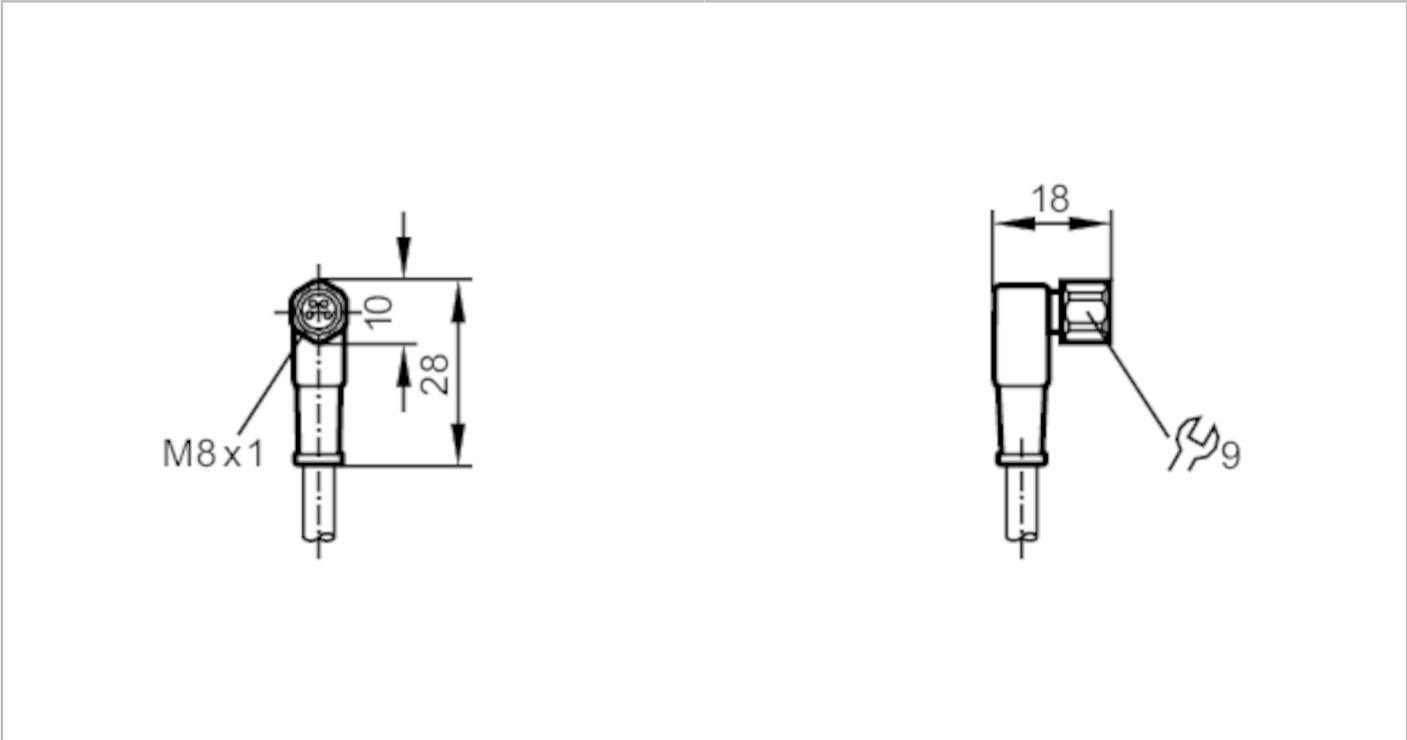

Application	
System	Free from silicone; gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 68
Mechanical data	
Material	PVC
Molded-body material	PVC
Material nut	stainless steel (1.4404 / 316L)
Remarks	
Pack quantity	1 pcs.

E11500



Female cordset


ADOAF030VAS0025E03

Electrical connection


Cable: 25 m, PVC, orange, Ø 5 mm; 3 x 0.25 mm² (32 x 0.1 mm)

Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

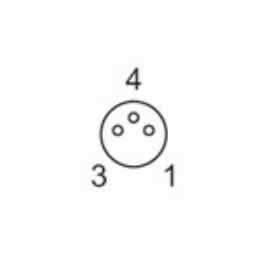

Connection

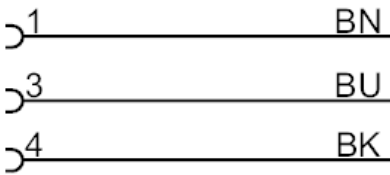

BK = Core colors :
BN = black
BU = brown
 blue