

E11501



Female cordset

ADOAF032VAS0005E03

Article no longer available - archive entry

Alternative articles: EVT131

When selecting an alternative article and accessories please note that technical data may differ!



Application

System	Free from silicone; gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage [V]	10...30 DC
Protection class	III

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature [°C]	-25...85
Protection	IP 68

Mechanical data

Dimensions [mm]	18 x 10 x 28
Material	PVC
Molded-body material	PVC
Material nut	stainless steel (1.4404 / 316L)

Displays / operating elements

Display	Switching status	1 x LED, yellow
	Power	1 x LED, green

E11501



Female cordset

ADOAF032VAS0005E03

Remarks

 
Pack quantity 1 pcs.

Electrical connection


Cable: 5 m, PVC, orange, Ø 5 mm; 3 x 0.25 mm² (32 x 0.1 mm)

Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Connection

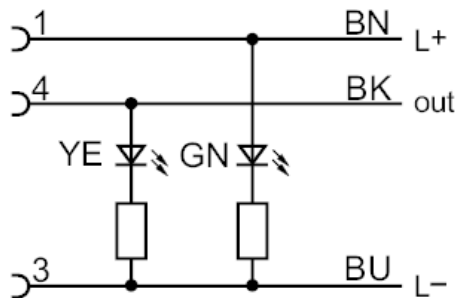

BK =
BN =
BU =

Core colors :
black
brown
blue