


E11503



Female cordset

ADOAF032VAS0025E03

Article no longer available - archive entry

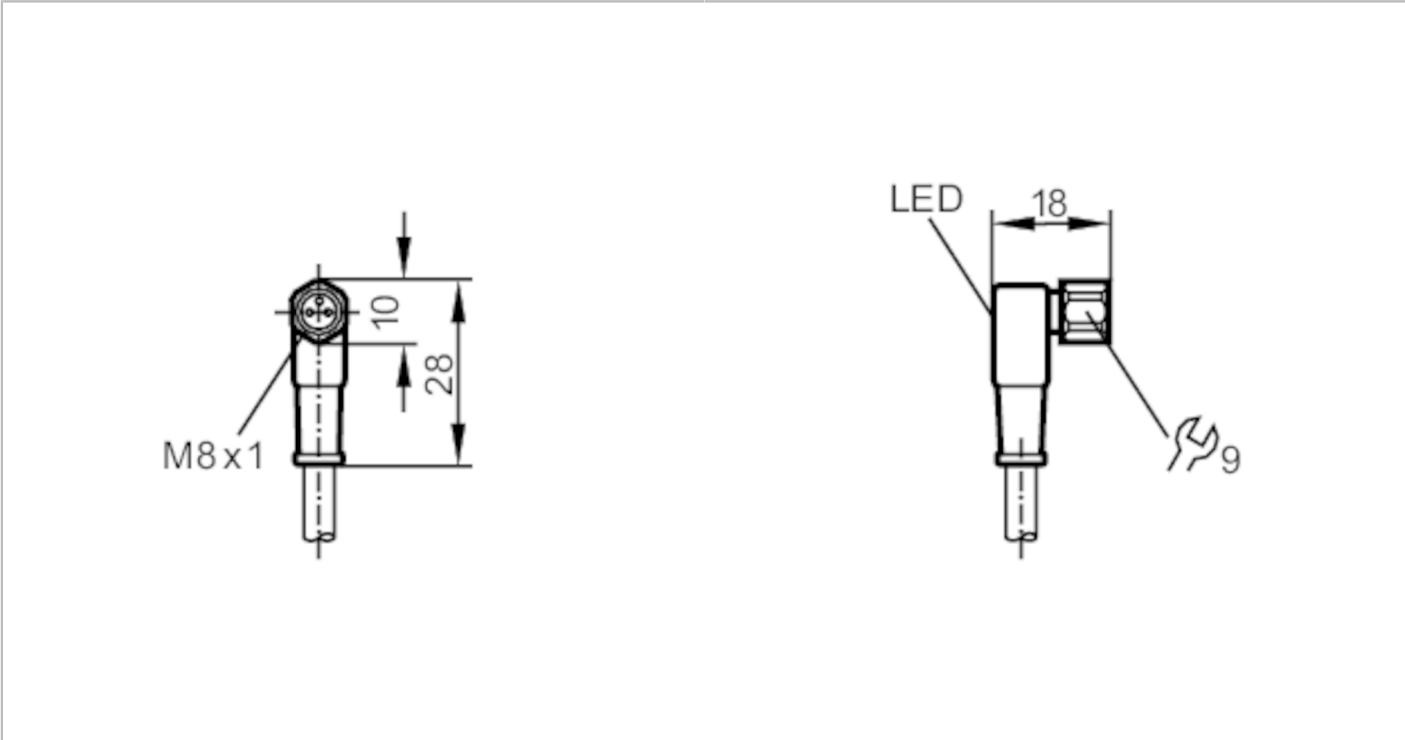

Application		
System	Free from silicone; gold-plated contacts	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class	III	
Outputs		
Electrical design	PNP	
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection	IP 68	
Mechanical data		
Dimensions	[mm]	18 x 10 x 28
Material	PVC	
Molded-body material	PVC	
Material nut	stainless steel (1.4404 / 316L)	
Displays / operating elements		
Display	Switching status	1 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity	1 pcs.	

E11503



Female cordset

 
ADOAF032VAS0025E03

Electrical connection


Cable: 25 m, PVC, orange, Ø 5 mm; 3 x 0.25 mm² (32 x 0.1 mm)

Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Connection

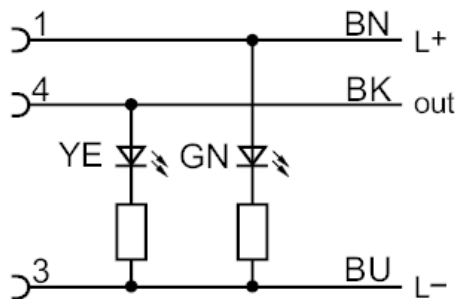

BK =
BN =
BU =

Core colors :
black
brown
blue