

# E11511




## Female wirable connectors

SDOGH050MSSFKPG

Article to be discontinued

Alternative articles: EVC814

When selecting an alternative article and accessories please note that technical data may differ!

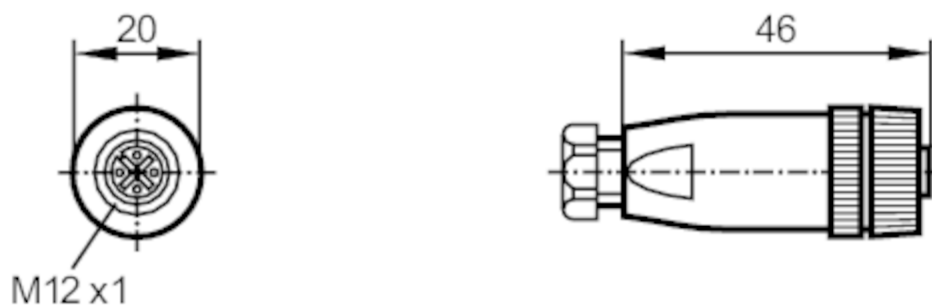

| Application             |      |  |
|-------------------------|------|--|
| System                  |      | Free from silicone; gold-plated contacts |
| Free from silicone      |      | yes                                      |
| Electrical data         |      |  |
| Operating voltage       | [V]  | < 45 AC / < 70 DC                        |
| Max. current load total | [A]  | 4; (...40 °C)                            |
| Operating conditions    |      |  |
| Ambient temperature     | [°C] | -25...85                                 |
| Protection              |      | IP 68                                    |
| Mechanical data         |      |  |
| Weight                  | [g]  | 29.2                                     |
| Dimensions              | [mm] | 20 x 20 x 46                             |
| Material                |      | PA                                       |
| Molded-body material    |      | PA                                       |
| Material nut            |      | brass, nickel-plated                     |
| Remarks                 |      |  |
| Pack quantity           |      | 1 pcs.                                   |

# E11511



## Female wirable connectors


SDOGH050MSSFKPG

### Electrical connection

screw terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

### Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: brass, nickel-plated; Contacts: gold-plated

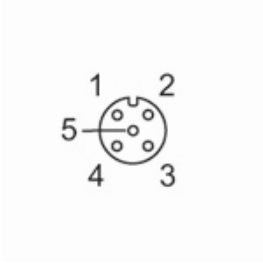

### Connection

