

# E11512




## Female wirable connectors

SDOAH050MSSFKPG

Article to be discontinued

Alternative articles: EVC815

When selecting an alternative article and accessories please note that technical data may differ!

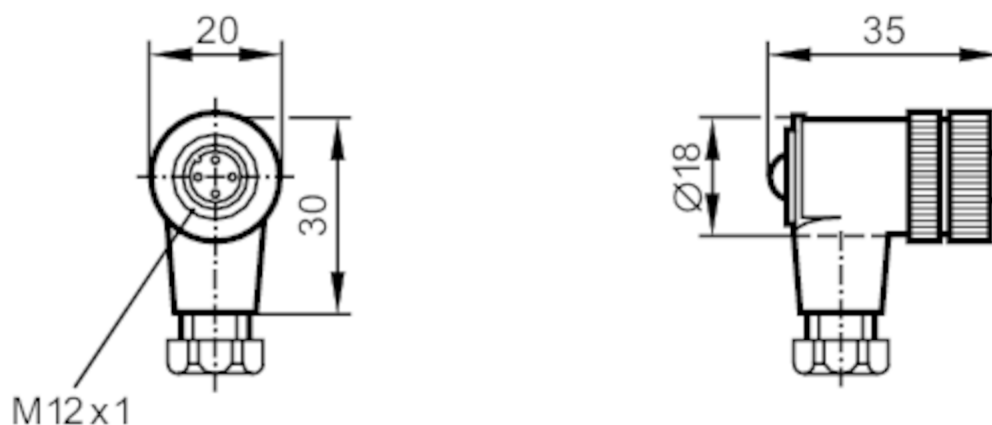

Application		
System		Free from silicone; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 45 AC / < 70 DC
Max. current load total	[A]	4; (...40 °C)
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 68
Mechanical data		
Weight	[g]	29.1
Dimensions	[mm]	35 x 20 x 30
Material		PA
Molded-body material		PA
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

# E11512



## Female wirable connectors


SDOAH050MSSFKPG

### Electrical connection

screw terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

### Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: brass, nickel-plated; Contacts: gold-plated

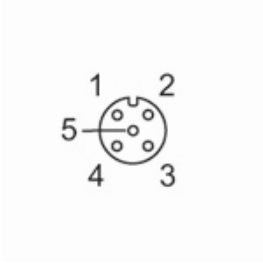

### Connection

