


E11535



Female wirable connectors

SDOAH030MSSFKPG

Article no longer available - archive entry

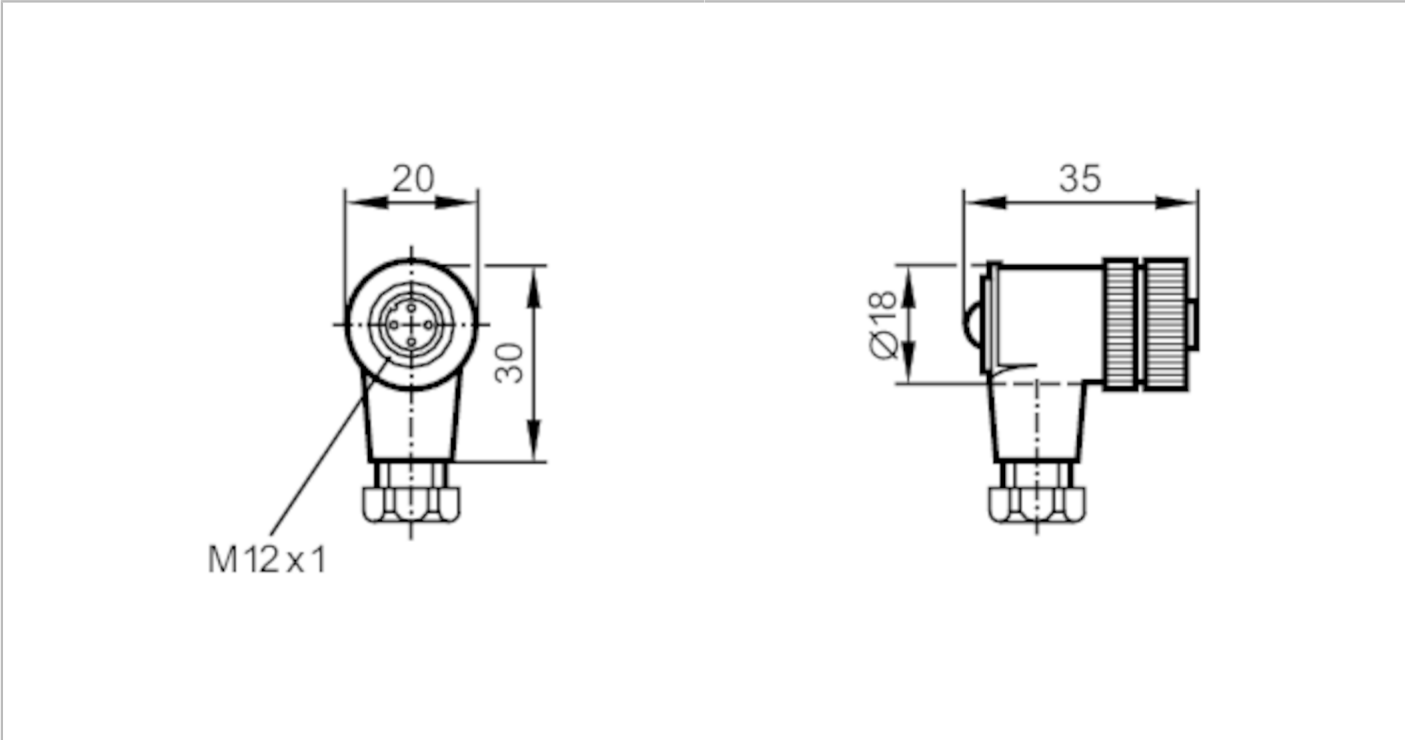

Electrical data		
Operating voltage	[V]	< 250 AC
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Weight	[g]	25
Dimensions	[mm]	35 x 20 x 30
Material		PBT
Molded-body material		PBT
Material nut		PA
Remarks		
Pack quantity		1 pcs.

E11535



Female wirable connectors

 
SDOAH030MSSFKPG

Electrical connection

screw terminals: ...0.75 mm²; Cable sheath: Ø 6...8 mm

Electrical connection - Socket

Connector: 1 x M12, angled; coding: C; Moulded body: PBT; Locking: PA



Connection

