

E11540




Female cordset

ADOGH040MSS0005C04

Article no longer available - archive entry

Alternative articles: EVC527

When selecting an alternative article and accessories please note that technical data may differ!

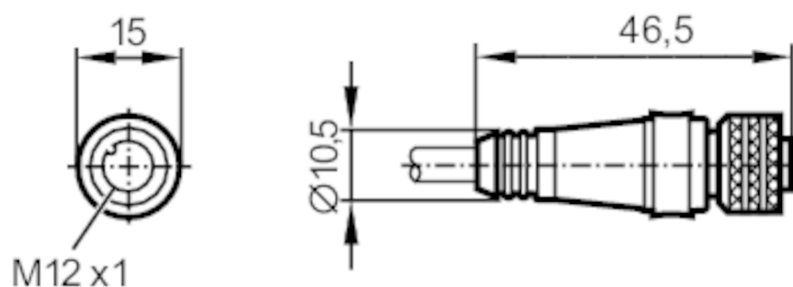

Application

System	Free from silicone; Halogen-free; gold-plated contacts; screened cable
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 50 AC / < 60 DC
Protection class		III
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	197.6
Dimensions	[mm]	15 x 15 x 46.5
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E11540



Female cordset

 
ADOGH040MSS0005C04

Electrical connection


Cable: 5 m, PUR, Halogen-free, black, Ø 5 mm, screened; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm; Shielded connection cable: shield not connected



Connection

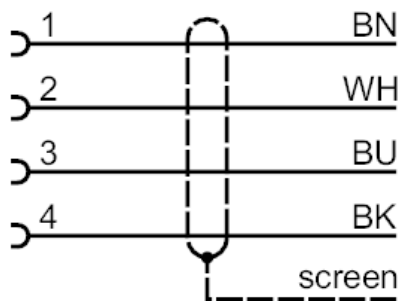

Core colors :
BK = black
BN = brown
BU = blue
WH = white