


E11542



Female cordset

ADOAH040MSS0005C04

Article no longer available - archive entry

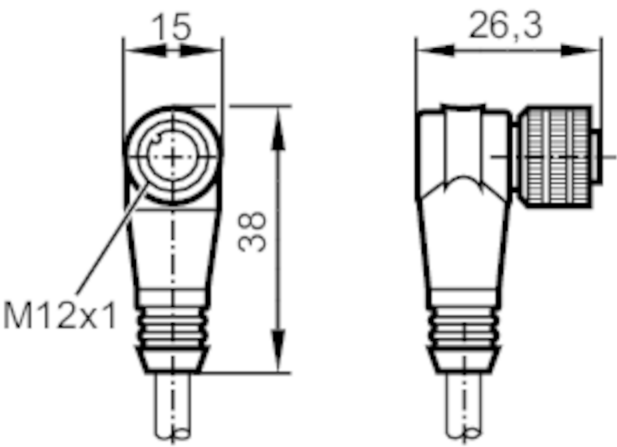

Application		
System		Free from silicone; Halogen-free; gold-plated contacts; screened cable
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 50 AC / < 60 DC
Protection class		III
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Weight	[g]	212.4
Dimensions	[mm]	15 x 26.3 x 38
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E11542



Female cordset

ADOAH040MSS0005C04

Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 5 mm, screened; 4 x 0.34 mm²

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm; Shielded connection cable: shield not connected



Connection



	Core colors :
BK =	black
BN =	brown
BU =	blue
WH =	white