


E11550



Wirable plug

SSTGF030MSSFPKG

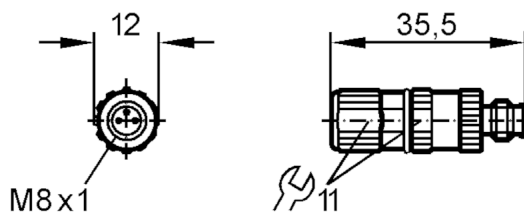

Application

Special feature	gold-plated contacts
Application	Industrial applications

Electrical data

Operating voltage	[M]	< 50 AC / < 75 DC
Protection class		III
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Weight	[g]	14.8
Material		Core insulation: PVC / TPE
Molded-body material		PA
Material nut		brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

insulation displacement technology: 0.14...0.38 mm²; Core insulation: PVC / TPE; (Ø 1.0...1.6 mm); Cable sheath: Ø 3...5 mm

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Contacts: 3, gold-plated; Moulded body: PA; Locking: brass, nickel-plated



E11550



Wirable plug

SSTGF030MSSFPKG

Connection

