


E11553



Female wirable connectors

SDOGF040MSSFPKG

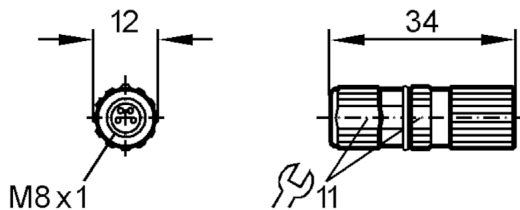

Application

| | |
|-----------------|-------------------------|
| Special feature | gold-plated contacts |
| Application | Industrial applications |

Electrical data

| | |
|-----------------------------|-------------------|
| Operating voltage [V] | < 45 AC / < 70 DC |
| Protection class | III |
| Max. current load total [A] | 4 |

Operating conditions

| | |
|--------------------------|----------|
| Ambient temperature [°C] | -25...90 |
| Protection | IP 68 |

Mechanical data

| | |
|----------------------|----------------------------|
| Weight [g] | 17.1 |
| Material | Core insulation: PVC / TPE |
| Molded-body material | PA |
| Material nut | brass, nickel-plated |

Remarks

| | |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

Electrical connection

insulation displacement technology: 0.14...0.38 mm²; Core insulation: PVC / TPE; (Ø 1.0...1.6 mm); Cable sheath: Ø 3...5 mm

Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Contacts: 4, gold-plated; Moulded body: PA; Locking: brass, nickel-plated



E11553



Female wirable connectors

SDOGF040MSSFPKG

Connection

